


FLKM 10...64



M 3

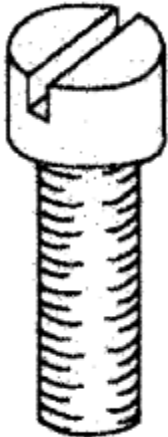

8

10 to 64-position

	(IEC)	rigid	flexible		I	U
	[mm ²]	solid	stranded	AWG	[A]	[V AC]
Connection data		0.2-4	0.2-2.5	24-12	1	60
UL				30-12	1	125
CSA (for FLKM 40)				28-12	1	125

CA

Description	No. of pos.	Module width [mm]	Type	Order No.	Pcs. Pkt.
VARIOFACE module , for mounting on 4 or 3, with pin strip as well as short and long engagement catches for socket strips	10	45.0	FLKM 10	22 81 01 8	10
	14	45.0	FLKM 14	22 81 02 1	10
	16	67.5	FLKM 16	22 81 03 4	10
	20	67.5	FLKM 20	22 81 04 7	10
	26	90.0	FLKM 26	22 81 05 0	5
	34	112.5	FLKM 34	22 81 06 3	5
	40	112.5	FLKM 40	22 81 07 6	5
	50	135.0	FLKM 50	22 81 08 9	5
	60	180.0	FLKM 60	22 81 09 2	5
	64	180.0	FLKM 64	22 81 10 2	5

Technical data

Dimensions

Height	58.5
Length	77
Standards/regulations	IEC 664/IEC 664 A/DIN VDE 0110; DIN VDE 0160 (in parts)

Type of housing

Polyamide PA non-reinforced

FLKM see [product-line info](#)

FLKMS color: green

Polyamide PA-F fiber reinforced

FLK see [product-line info](#)

color: green

Torque value of terminals see [product-line info](#).

The rated cross section (see [product-line info](#)) refers to untreated conductors without ferrules.

Articles printed in bold can be delivered at short notice.