



MiniMark™ INDUSTRIAL LABEL PRINTER




A COMBINATION OF COLOURS AND MATERIALS

Printing on adhesive banners of different colours or die-cut labels for multiple uses (labels for directional, safety, and informational purposes, management of production, stocks and fixed assets, HSID labels, bar codes ...).

ADHESIVE MATERIALS

INDUSTRIAL : 35 metres in length.

Tapes are available in a large selection of colours and three widths 29, 57 and 100mm to meet all your labelling requirements.

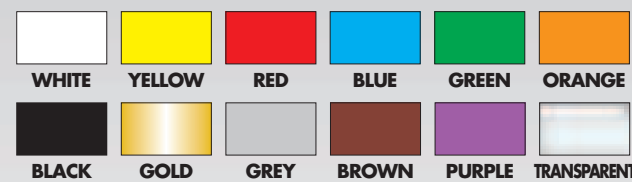


STANDARD : 35 m in length.

Colours: White and Yellow.

Available in 3 widths :

5, 50 and 75 mm

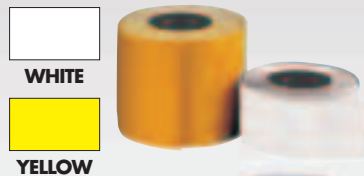

DIE-CUT LABEL ROLLS :

(number and sizes of labels vary by roll) Available in Thermal paper, Vinyl film and Polyester – white or metallic in colour. HSID labels also available in different formats and materials.

THERMAL TRANSFERS

90 metres in length.

5 colours for monochrome printing: black, white, red, blue, green.



YOUR BRADY SPECIALIST



MARKWARE™ SOFTWARE

Markware™, powerful software for label and sign creation for safety, informational and directional signage is the tool to best complement your use of the MiniMark™.

11 LANGUAGES : English, French, German, Dutch, Spanish, Portuguese, Italian, Danish, Swedish, Norwegian, and Finnish.
OPERATING SYSTEM : Windows 98 (2nd Edition) 2000 – XP, NT (Requires Service Pack 6)

MINIMUM PROCESSOR CONFIGURATION : Pentium®1

RAM : 32 MB minimum (128 MB recommended)

LIBRARY : Over 1000 symbols, Pictograms and pre-set formats: rules and requirements, danger, prohibition, fire, hazardous substances, transportation, information...

15 BAR CODE PROTOCOLS : Codabar, code 128 Auto, code 128 A, code 128 B, code 128 C, code 39, EAN/JAN-13, EAN/JAN-18, Extended code 39, HIBC, Interleaved 2/5, UPCA, UPCE 11 Digit, UPCE-0 6 digit, UPCE-1 6 digit.

FUNCTIONS : All True Type Fonts installed on a PC

FUNCTIONS : Negative printing / Mirror Printing / Puzzle Printing / Object Rotation / Data import (for formats Excel®, Access®, Dbase®, text®, FoxPro®, Lotus®, Paradox®) / Importing of drawings, pictograms, and diagrams in BMP, DIB, TIF, JPG, WMF, PNG, PCX, PCT, RAS, and EPS file types.

MINIMARK™ PRINTER

PRINTING METHOD : Thermal Transfer + Direct Transfer

RESOLUTION : 203 DPI

MEMORY : 2MB DRAM / 2MB flash ROM

CUT : Integrated, automatic

PRINTING SPEEDS : up to 4 inches per second

PORTS : Parallel + USB + serial

MAXIMUM PRINTING WIDTH : 104 mm

MINIMUM PRINTING LENGTH : from 25 mm to 1 m

ACCEPTED PRINTING MATERIALS : Vinyl, Polyester, banner paper + die-cut labels

DIMENSIONS : W: 201 mm x D: 260 mm x H: 179 mm

WEIGHT : 2,2 Kg

CURRENT : Input : 100-240V / 50/60Hz / 1.6A

Output : 24 VDC - 2.5 A



710120 ENGLISH



Brady Corporation Ltd - Wildmere Industrial Estate
Banbury - Oxon - OX16 3JU - Telephone: Customer
Services 01295 228288 - Main Reception: 01295 228200
Fax: 01295 228100 - www.minimark.co.uk

Sometimes - something small can have a powerful impact



MiniMark™ INDUSTRIAL LABEL PRINTER



BRADY, THE REFERENCE FOR IDENTIFICATION



PORTABLE
MONOCHROME



COMPACT PERIPHERAL
UNIT MONOCHROME



MONOCHROME
TOUCH SCREEN
FREESTANDING
MONOCHROME



MULTICOLOUR
TOUCH SCREEN
FREESTANDING
COLOUR



COLOUR & CUT
TOUCH SCREEN
COLOUR AND CUT

MULTICOLOUR
LARGE SIZE

© 2005 W.H. BRADY Co. All Rights Reserved

A printer to meet your demands

MINIMARK™
INDUSTRIAL LABEL PRINTER

Ease of use, high print quality, compact size...

The MiniMark™ Solution is the ideal blend of user-friendliness and creativity at a competitive cost. At last, a solution for everyone.



Avoid accidents with proper identification!



Label your warehouse stock effectively.



Identify pipelines on-site!



For greater impact, personalise your messages.

ADAPTED TO ALL OF YOUR NEEDS :

- ✓ SAFETY SIGNS
- ✓ PIPE MARKERS
- ✓ MANAGEMENT OF FIXED ASSETS
- ✓ INFORMATIONAL AND DIRECTIONAL INFORMATION
- ✓ IDENTIFICATION OF HAZARDOUS SUBSTANCES
- ✓ MAINTENANCE

MarkWare™

Demand simplicity

Ease of use

Markware™, the companion software indispensable for use of the Minimark™, is a powerful and effective tool in industrial signage.

It provides over 600 standardised symbols and more than 500 formats.

With it, you are supported through every stage of your creation.

Personalising signage

Personalise your messages (logos, texts...) with great ease, so that your signage at last achieves the attention it deserves. Everything changes when you are seen and understood clearly!

Compliance with European standards

To print pipemarkers, just select the standard that applies to your country and simply follow the instructions. Markware™ guarantees you immediate compliance, with time savings the result. Demand simplicity and peace of mind.



There's no catch to these savings...

Ease of use and minimal required space

Time-saving, user-friendly: qualities that help simplify your life. From your PC you can effectively create your own messages, symbols, pictograms, bar codes, mailing labels, pipe markers, signage...

Minimal investment, maximum effectiveness

Purchasing labels externally often proves to be a long, expensive process. Furthermore, the lack of safety signage can be at the root of serious accidents. Don't be dependent on others any longer. For a minimal investment you can both economise and be more effective.

Variety of print media

Printing on adhesive banners or die-cut labels allows for multiple uses (indicator signs, safety labels, production management, stock and fixed assets management...). Put an end to wasted time! Your organisation comes out ahead in both clarity and productivity.

