


# manifold rail

## VABM-L1-10AW-M7-4

Part number: 566548

FESTO

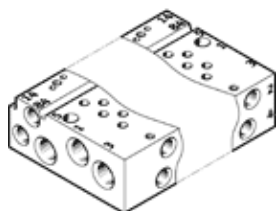

### Data sheet

Feature	Value
Grid dimension	10.5 mm
Max. number of valve positions	16
Operating pressure	-0.9 ... 10 bar
Authorisation	RCM Mark c CSA us (OL) c UL us - Recognized (OL)
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Max. tightening torque, H-rail mounting	1.5 Nm
Max. tightening torque, valve mounting	0.45 Nm
Max. tightening torque, wall mounting	1.5 Nm
Product weight	96 g
Auxiliary pilot air port 12/14	M5
Pilot exhaust port 82/84	M5
Pneumatic connection, port 1	M7
Pneumatic connection, port 2	M5
Pneumatic connection, port 3	M7
Pneumatic connection, port 4	M5
Pneumatic connection, port 5	M7
Materials note	Conforms to RoHS
Material manifold	Wrought Aluminium alloy