


distributor block

FR-12-PK-3-B

Part number: 8761

FESTO

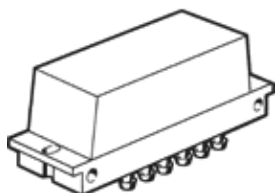

Data sheet

Feature	Value
Nominal size	2.5 mm
Assembly position	Any
Operating pressure complete temperature range	0 ... 8 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Number of outputs	12
Number of supply lines	1
Pneumatic connection, port 1	Female thread 1/4
Pneumatic connection, port 2	For tubing outside diameter 4 mm
Materials note	Conforms to RoHS
Material housing	Aluminium die cast