

ARCADE LOW

PS 90635 6D K 4 S3S SR ESD




SPECIFICATIONS

UPPER	water-repellent nubuck + CORDURA® + quick fastening system
LINING	BIFRESH PLUS 3D lining with high breathability and top abrasion resistant
TOE-CAP	fiberglass
NAIL PROTECTION	Zero Perforation fabric, metal-free
SOLE	dual density PU with scuff-cap
INSOLE	SUPPORT ACTIVE ESD
SIZES	39/48
FIT	Mondopoint 12
SAFETY NORMS	EN ISO 20345:2022
WEIGHT (SIZE 42)	1,5 Kg

WORK ENVIRONMENTS

Automotive / Logistics / Agriculture / Craftmanship / Electronics / Gas and Explosives / Light Industry / Engineering / Mechatronics

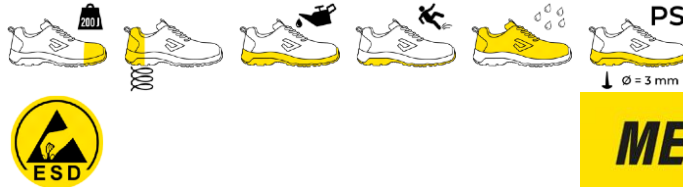

DESCRIPTION

ARCADE LOW is a heavy duty boot ESD, class protection S3S FO SR with a water-repellent nubuck upper and an abrasion resistant scuff-cap, equipped with a heel Stability System and quick fastening system

COMPONENTS

Polyurethane insole with activated carbons ensures maximum hygiene avoiding the proliferation of fungi and bad odours. Anti-static, anatomic, provides excellent support along the plantar arch, ensures maximum comfort and absorption of the impact energy. Made with a compounds of EPA material (low electrical resistance)

Its weight reduced by over 50%, and the high impact and compression performance, make it the perfect choice for those looking for safety and lightness. Particularly suitable in areas where metal is not allowed

PLUS

CORDURA®: High performance fabric with excellent rip and wear resistance. Provides excellent performance of water repellency and breathability

BIFRESH PLUS: Three-dimensional Polyester lining with high abrasion resistance and breathability

CORDURA®

BIFRESH®
KEEP IT COOL

METAL FREE

TOE-CAP



INSOLE



STANDARD LABEL



Calzaturificio 5Bi S.r.l.
Via Trani, 94-100
76121 Barletta (BT)

PS 90635 6D K 4

42

bicap.it

S3S SR



Year and month of manufacture

Lot / Batch Number

EN ISO 20345:2022



do not re-use