





ENGLISH

Anti Vibration Sandwich Mount

The SM Mount is suitable for both compression and shear load applications or both by fitting them in a 'V' arrangement. It is available in either 50, 60 or 70 shore hardness. These mounts have a bonded interleaf which increases the load carrying capacity.

Applications include use in heavy plant and machinery, generator sets etc.

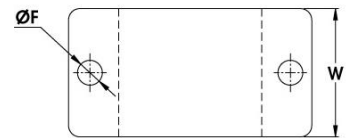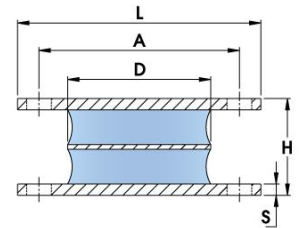

H = Height

D = Diameter

RS Code	Item Code	Description	Metal	D (mm)	H (mm)	Max Compression Load (kg)	Max Deflection (mm)
1712645	SM10843-1.5	Sandwich Mount 108x43 50 ShA NR	Mild Steel	108	43	180	3
1712646	SM10843-2	Sandwich Mount 108x43 60 ShA NR	Mild Steel	108	43	280	3
1712647	SM16843-1.5	Sandwich Mount 168x43 50 ShA NR	Mild Steel	168	43	450	3
1712648	SM16843-2	Sandwich Mount 168x43 60 ShA NR	Mild Steel	168	43	700	3
1712649	SM16843-3	Sandwich Mount 168x43 70 ShA NR	Mild Steel	168	43	1030	3