


170973 DFM-100-200-P-A-KF Guided drive - Series from 04-2023

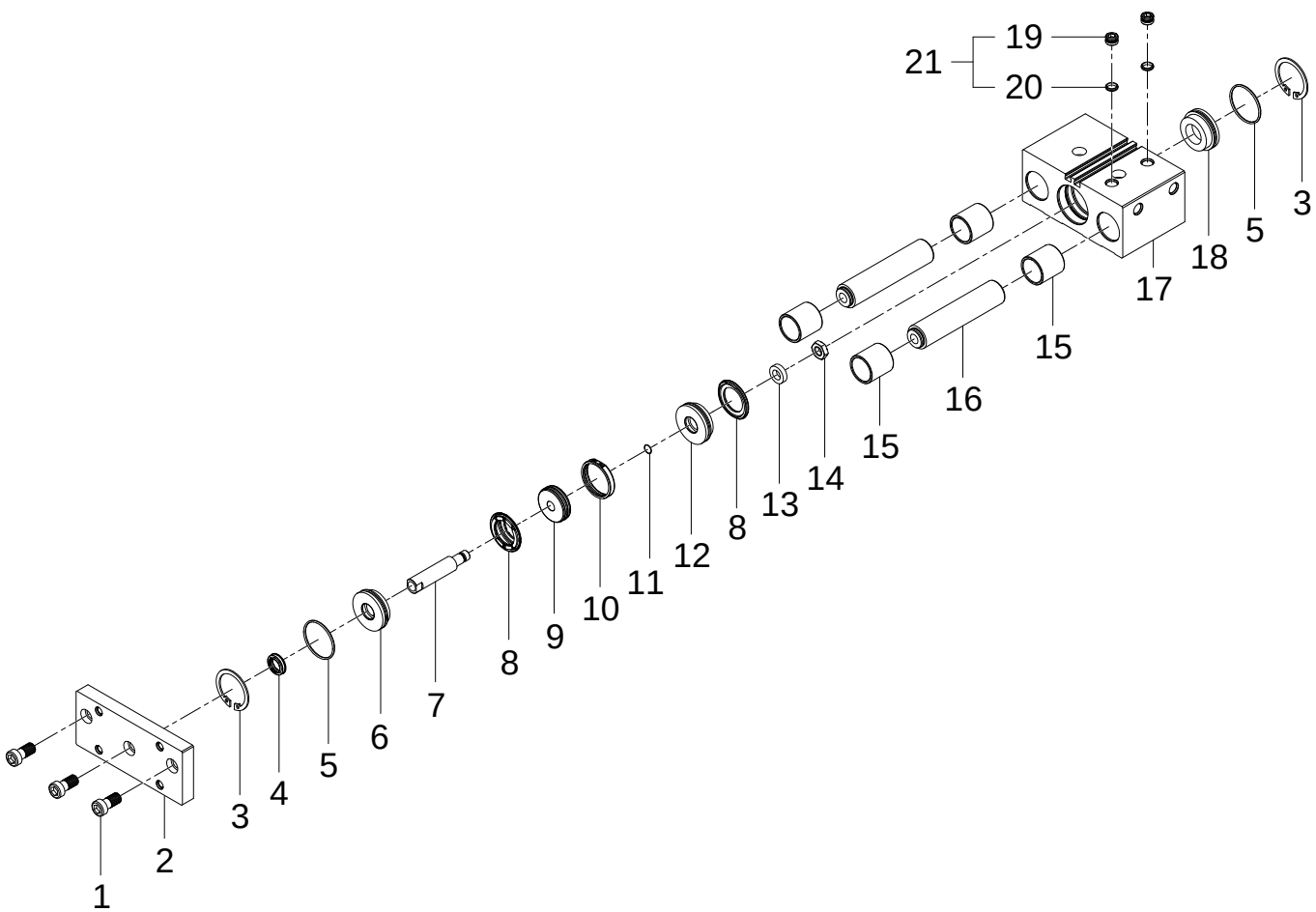

170973 DFM-100-200-P-A-KF Guided drive - Series from 04-2023

Pos.	Part no.	Type	Note	Qty.	Unit
A	394803	DFM-100-PA Set of wearing parts	Spare parts: 4, 5, 8, 11, 20 ▶ Replacing the wearing parts	1	PC
1		DIN 6912-M16X30-8.8 Socket head screw	Not available Use locking compound 8181256 CYBERBOND TM44 Tightening torque 120 Nm / 88.5 lbf ft	3	PC
2	8140608	DFM-100 End plate		1	PC
3	229760	DIN 472-102X4 Retaining ring		2	PC
4		WIFC1-25X30X4,6-TPE-U Wiper seal	Not available separately, see position A Lubricate with 684474 LUB-KC1 during assembly	1	PC
5		B-99X1,5-N-NBR70 O-ring ISO3601	Not available separately, see position A Lubricate with 684474 LUB-KC1 during assembly	2	PC
6	713459	DFM-100 Bearing cap		1	PC
7	8157675	IRA-25-S0238.7-B Piston rod		1	PC
8		DFM-100 Piston seal	Not available separately, see position A Lubricate with 684474 LUB-KC1 during assembly	2	PC
9		AEVU-100 Piston magnet	Not available	1	PC
10	338258	96,75X88X5,7 Ring magnet		1	PC
11		B-17X1,5-N-NBR70 O-ring ISO3601	Not available separately, see position A Lubricate with 684474 LUB-KC1 during assembly	1	PC
12		ADVU-100 Piston	Not available	1	PC
13	338341	18X36X6-1.0330 Disc		1	PC
14	213600	DIN 439-B-M16X1,5-A2-70 Hex nut	Use locking compound 8181256 CYBERBOND TM44 Tightening torque 45 Nm / 33.2 lbf ft	1	PC
15		30X40X50:LBBS30-2LS Ball bushing	Not available	4	PC
16	8169319	DFM-100-200-KF Guide rod		2	PC
17		DFM-100-200 Housing	Not available Lubricate with 684474 LUB-KC1 during assembly	1	PC
18		DFM-100-...-P-A End cap	Not available	1	PC
19		G3/8A Plug screw	Not available separately, see position 21	1	PC
20		12,5X15,3X3,6 Sealing ring	Not available separately, see position 21+999 Lubricate with 684474 LUB-KC1 during assembly	1	PC
21	116517	G3/8 Plug screw		1	PC