
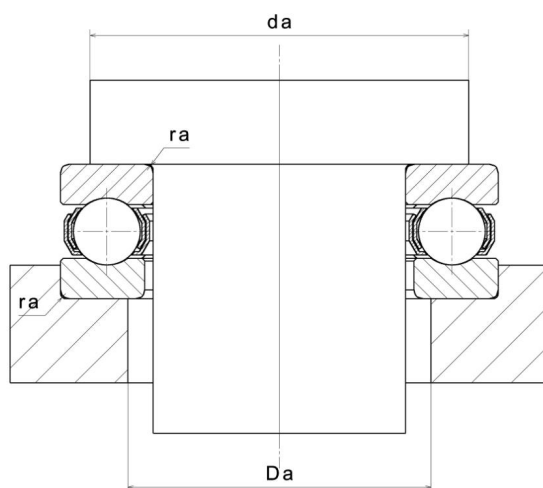


Technical data

51230

One direction thrust ball bearings

VISUAL (S)

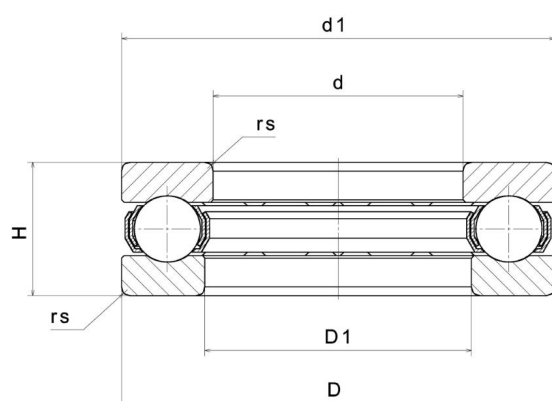

PRODUCT DEFINITION

Brand	NTN
d - Internal diameter	150 mm
D - External diameter	215 mm
T - Thrust bearing height	50 mm
rs - Min fillet radius	1,5 mm
Mass	5,87 kg

PRODUCT PERFORMANCE

Ca - Dynamic axial load rating	227000000 mN
C0a - Static axial load rating	720000000 mN
Cua - Limit axial load rating	24000000 mN
N lim - Oil lubrication limit speed	7800 °/s
N lim - Grease lubrication limit speed	5400 °/s
Tmin - Min operating temperature	233,15 °K
Tmax - Max operating temperature	393,15 °K

ABUTMENT

Da max - Max shoulder diameter OR	176 mm
da min - Min shoulder diameter IR	189 mm

