


PREVOST FILTRATION - KOMBINATIONEN VON EINHEITEN

Doppelblock - Filterregler und Öler

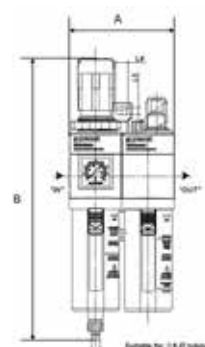

Max. Betriebsdruck
10 bar

Filterung (µm)
25.00

Min/Max Temperatur
5 / 50 °C

Art. Nr	IG	Durchfluß bei 6 bar (l/min) (ΔP= 1.00 bar)		Nettogewicht (Kg)
ATU B2585100	G1/8	400	0.5 / 8.5	0,687
ATU B2585101	G1/4	700	0.5 / 8.5	0,687
ATU B2585102	G3/8	2000	0.5 / 8.5	2,073
ATU B2585103	G1/2	3300	0.5 / 8.5	2.073