



- Magnetic glassboard surface (4 mm)
- Can be written on with Legamaster chalk markers and Legamaster board markers
- Legamaster glassboards can be mounted horizontally and vertically
- Available in colours white, black, red and blue
- Concealed wall mounting (40x60 and 60x80 cm) or wall mounting brackets (90x120 and 100x150 cm)
- Optional marker tray 200 mm (ref. 7-126800) is easily fixed to the glassboard with a strong adhesive strip




Coloured glassboard

90 x 120 cm blue

- Minimalistic colourful and decorative glassboard with all functionalities of a standard memoboard / whiteboard
- Tempered safe glass (4 mm)
- Perfect smooth writability
- Very good to excellent dry-wipeability: write on/ dry wipe surface is guaranteed for 25 years when used in combination with Legamaster accessories
- Hygienic glass surface that is easy to clean and keep clean with Legamaster whiteboard and glassboard cleaner
- Legamaster glassboards come with 2 superstrong glassboard magnets (diam. 12 mm), one Legamaster chalk marker, fixing kit and a clear mounting instruction (white glassboards: black marker, all other colours: white marker)
- Remove permanent marker ink: can be used with Magic-Wipe


Ref.: **7-104854**

EAN: **8713797078962**

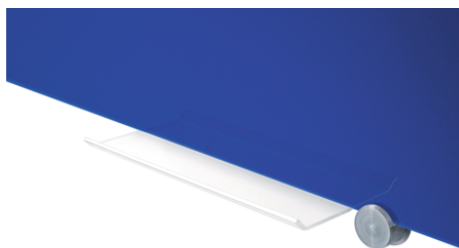

Recommended accessories

- Glassboard Starter kit Ref.:7-125200
- Marker tray plexi glass coloured glassboard Ref.:7-126800

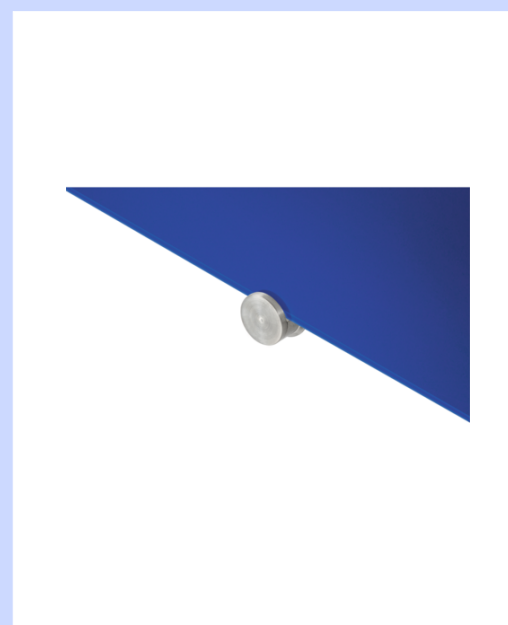

Product specifications

Surface (material/color)	Safety glass / Blue
Magnetic	Yes
Product dimensions	W: 1200 x H: 900 x D: 4 (mm)
Mounting type	Wall (brackets)
Included accessories	One chalkmarker, Two strong glassboard magnets
Product warranty	2 years
Surface warranty	25 years

Product logistics

Product SAP / EAN / KEA	867501000 / 8713797078962 / 7-104854
Packing Unit	Piece
Quantity	1
Packing dimensions	W: 1290 x H: 990 x D: 50 (mm)
Weight (gross/net)	16.00 kg / 13.28 kg