

### Features

- Crocodile Clips
- Accepts standard phone tip or test prod tip
- Jaw open 0.31" (7.9mm) max
- Material: Nickel-Plated Steel
- Length: 1.97" (50 mm)
- Rating: 10 Amps

### RS PRO Crocodile Clips, Steel Contact, 10A

RS Stock No.: 0205409



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

### Product Description

Buy this product from [www.rspro.com](http://www.rspro.com)

# Crocodile Clips



• RS alligator clips with barrel and screw termination types, suitable for test lead termination and other applications that require quick connect and disconnect alligator clips, in copper, stainless steel and nickel plated steel versions.

• This Electric Heavy Duty, General Purpose, Crocodile and Alligator Clips

• A concise offering of steel and copper alligator and crocodile clips from RS suitable for applications including grounding clips, test meters clips, battery terminal connection and many others that require a durable and hardwearing alligator or crocodile clip

## General Specifications

Material	Nickel-Plated Steel
Product Name	Phone Tip Alligator Clip
Type	General Purpose Clip
Insulated	No
Connection Type	Accepts standard phone tip or test prod tip

Commented [波辛1]:

## Electrical Specifications

Current rating	10A
----------------	-----

## Mechanical Specifications

Jaw Opening (±10%)	0.31" (7.9mm) max
Contact Material	Nickel-Plated Steel
Insulation Material	No
Dimensions (±10%)	Overall length 1.97" (50 mm)


## Approvals

# Crocodile Clips



Standards Met	RoHS Compliant
Declarations	Reach

## Spec Drawings Diameter

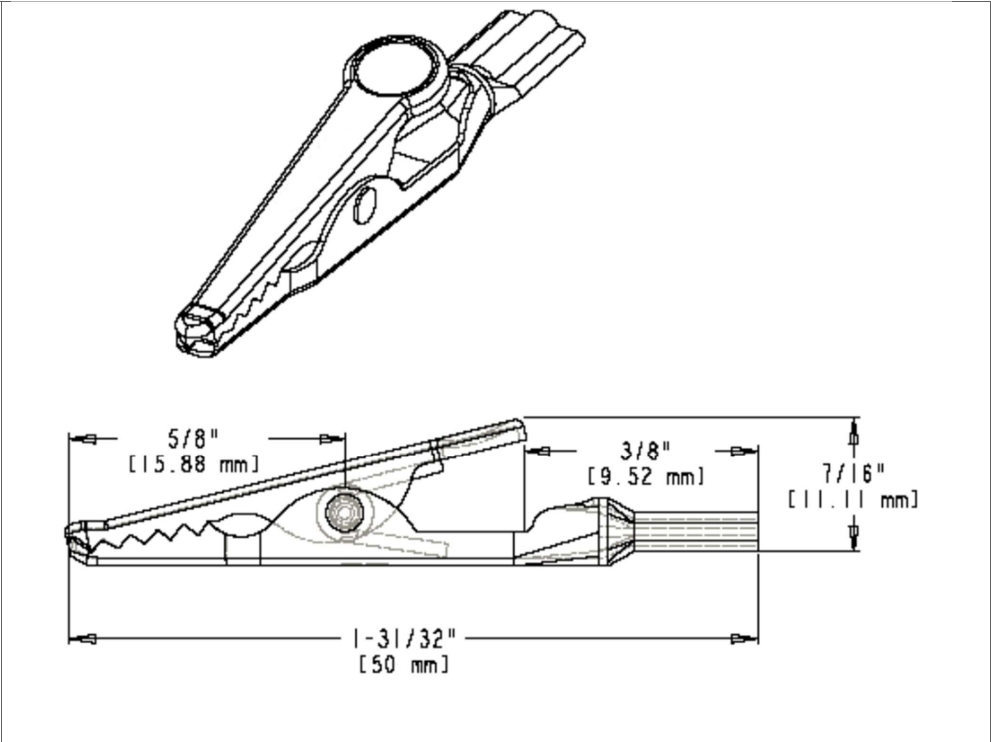

PRODUCT DIMENSION DRAWING AND ADDITIONAL INFORMATION