



SITOR cylindrical fuse link, 22x127 mm, 10 A, gS, Un AC: 1500 V, Un DC: 1000 V

Figure similar

Model		
product brand name	SENTRON	
product designation	SITOR cylindrical fuse link	
General technical data		
operating class of the fuse link	gS	
type of voltage of the operating voltage	AC	
supply voltage at DC	1 000 V	
Main circuit		
operational current rated value	10 A	
Product details		
product component striker	No	
Mechanical Design		
mounting position	Any, preferably vertical	
net weight	111 g	
Approvals Certificates		
General Product Approval	other	Environment




[Confirmation](#)

[Environmental Con-
firmations](#)

[Environmental Con-
firmations](#)

Further information
Information on the packaging https://support.industry.siemens.com/cs/ww/en/view/109813875
Information- and Downloadcenter (Catalogs, Brochures,...) http://www.siemens.com/lowvoltage/catalogs
Industry Mall (Online ordering system) https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3NC2310-0MK
Service&Support (Manuals, Certificates, Characteristics, FAQs,...) https://support.industry.siemens.com/cs/ww/en/ps/3NC2310-0MK
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...) http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NC2310-0MK
CAX-Online-Generator http://www.siemens.com/cax
Tender specifications http://www.siemens.com/specifications

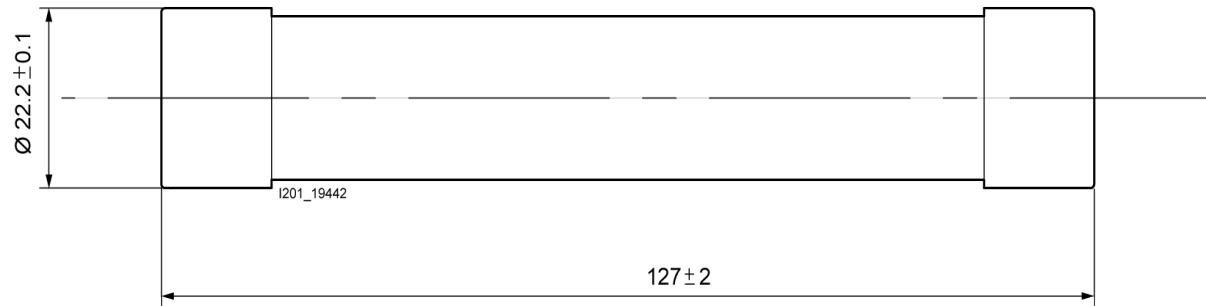

last modified:

4/11/2025 

