

## Datasheet

### Red Cap Tactile Switch

RS Stock number 734-7375



#### Specifications:

Mechanical Life: 1,000, 000 cycles

Contact Resistance: 100m $\Omega$  max. (initial)

Insulation Resistance: 1000M $\Omega$  min.

Dielectric Strength: 1,000VAC

#### MATERIALS

Switch Housing: PBT


Transparent: ABS

Contact: Stainless, Au version NI plated






Terminals: Brass, Au version NI plated

Terminal Seal: Epoxy


Dimensions – inch  
mm

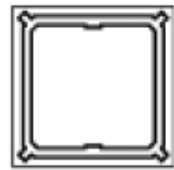

$15.00 \pm 0.1$

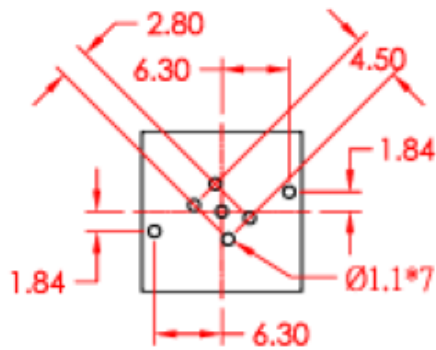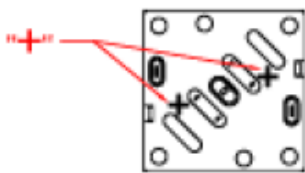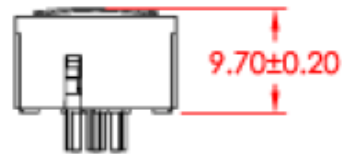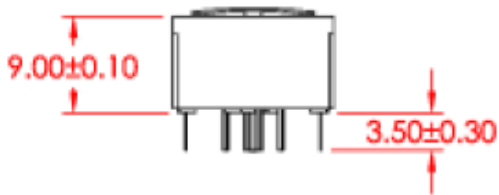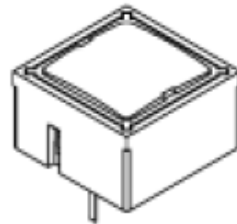

P.C. MOUNTING

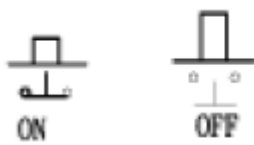

SCHMATIC