

# Actuator

704.733.0

Distribution by  
Rs-online<https://rs-online.eao.com/p/704.733.0>

Your product:

---



## 704.733.0 Actuator

### FRONT

**Front dimension:** 30 mm x 30 mm

**Front form:** Square

### MOUNTING

**Design:** Raised

**Mounting type:** Panel mounting

### ELECTRICAL CHARACTERISTICS

**Standards:** The switches comply with the "Standards for low-voltage switching devices" DIN EN 60947-1

### MECHANICAL CHARACTERISTIC

**Weight:** 0.009 kg

### AMBIENT CONDITION

**IP Protection:** IP65 front side

**Operating temperature:** – 40 °C ... + 55 °C

**Storage temperature:** – 40 °C ... + 85 °C

### CERTIFICATE

**REACH:** REACH compliant

**RoHS:** RoHS compliant

## OTHER

**Short Description:**

Actuator, 30 mm x 30 mm, Square


**Housing colour:**

Black


**Housing material:**

Plastic

**Wiring diagrams:**

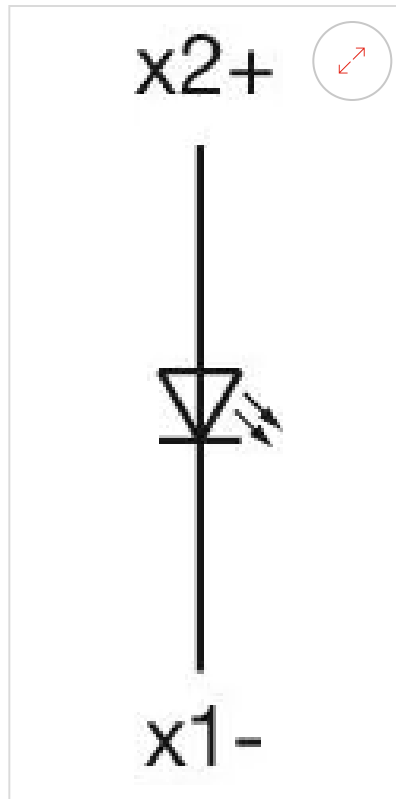

**Mounting cut-outs:**

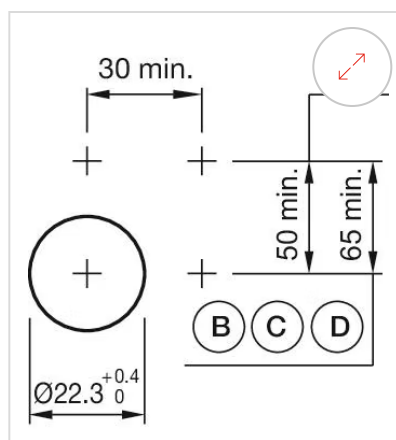


A = Screw terminal

B = Push-in terminal (PIT)

C = Plug-in terminal 6.3 mm x 0.8 mm


D = Double plug-in terminal 6.3 mm x 0.8 mm

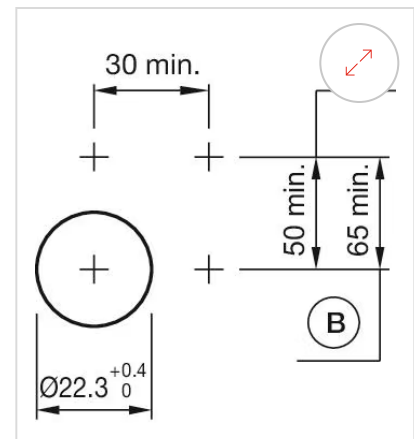


A = Screw terminal

B = Push-in terminal (PIT)

**Dimension drawings:**

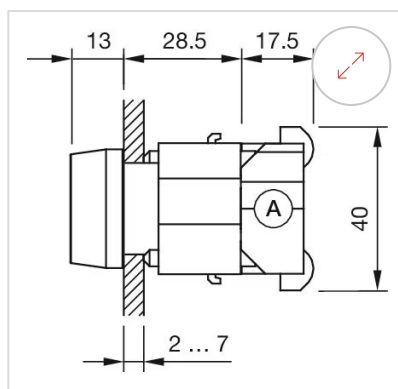

A = Screw terminal

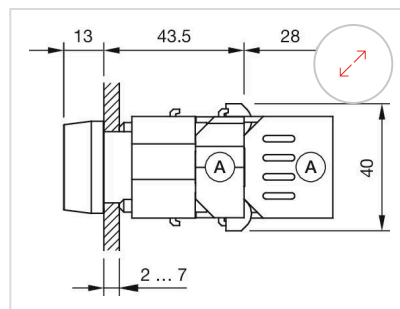

X = Screw terminal