


DOC NO	ISSUE	REVISION	PRODUCT REF.	DATE	QUALITY PLAN
QF/RD/05	01	00	FAR0701	26.11.14	
<b>TECHNICAL SPECIFICATIONS</b>				<b>SIGNATURE</b>	
				<b>PRESIDENT (TECHNICAL)</b>	

### MICRON BLOCK (FAR0701)

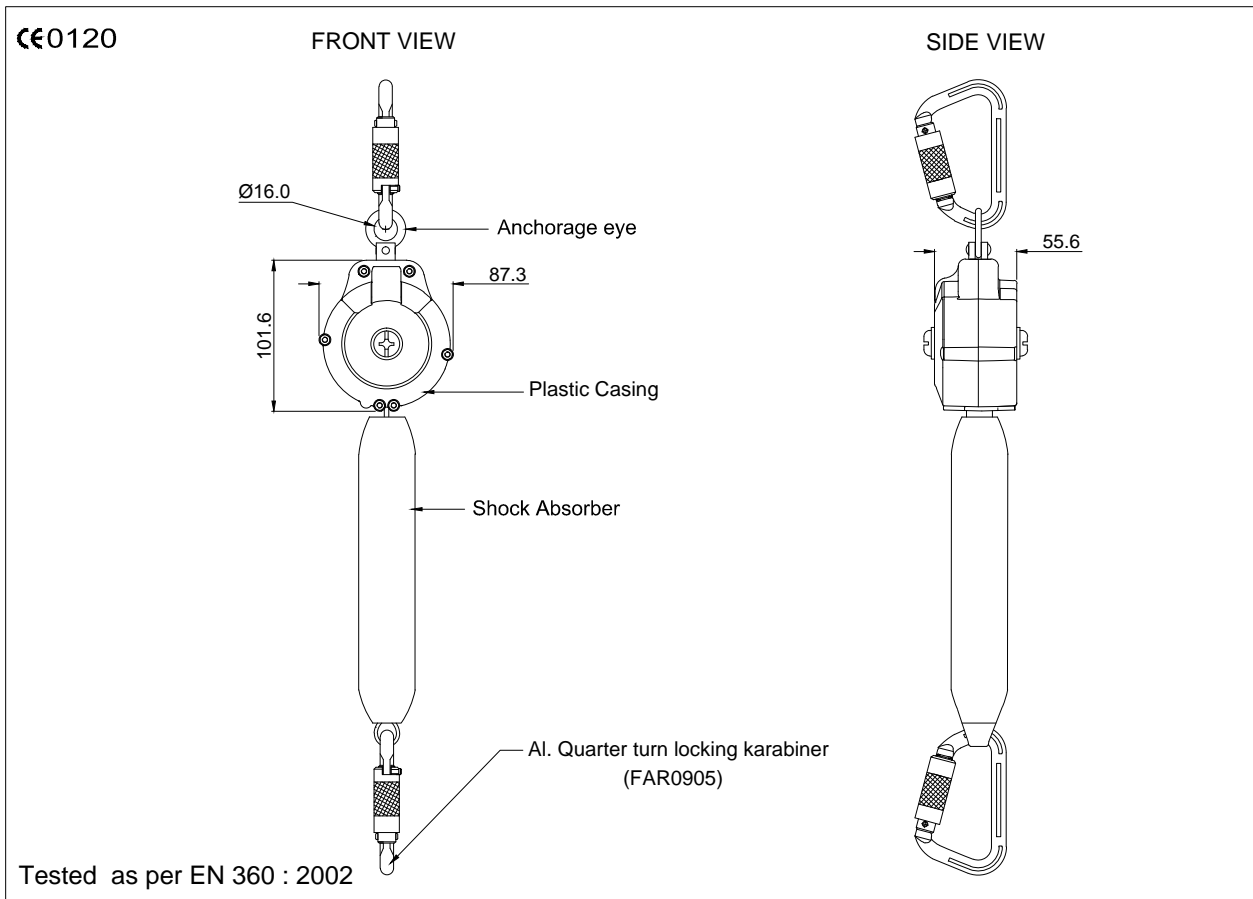

**PHYSICAL PARAMETERS**

- Lightest available SRL in it's range/class.
- Robust & durable plastic casing.
- Aluminium Quarter turn Locking Karabiner at attachment end (Our ref. FAR0905).

**LENGTH**

- Max. 2 meter.

**WEBBING**

- Material : Technora
- Width : 21.0mm.
- Minimum Breaking strength : 20 kN OR 2,039 kgf

**VITAL TEST COMPLIANCE**

- Static Strength : 15 kN for 3 Minutes.
- Dynamic Performance : 100 kg mass free fall with the Breaking force of less then 6 kN & arrest distance less then 2 meter.

**WEIGHT**

- 848.5 gms ±20 gms .

