



# Product data sheet

Power tools for trade & industry

Cordless Angle Drill

## PRO GWB 12V-10



Compact angle drill in the 12 V category for hard-to-reach places

### The most important data

Torque (soft/hard/max.)	3/11/- Nm
Battery voltage	12.0 V

**Order number** 0 601 390 909

## Technical data

### Additional data

Battery voltage	12.0 V
Torque (soft/hard/max.)	3/11/- Nm
Weight excl. battery	1.2 kg

## Noise/vibration information

### Drilling in metal

Vibration emission value ah	3.5 m/s <sup>2</sup>
Uncertainty K	1.5 m/s <sup>2</sup>

### Screwdriving

Vibration emission value ah	3.5 m/s <sup>2</sup>
Uncertainty K	1.5 m/s <sup>2</sup>



**BOSCH**


Invented for life

# Product data sheet

Power tools for trade & industry

## Advantages:

- Extremely versatile, 5-position-pivoting head can be adjusted to fit each specific worksite
- Slim, soft grip handle and extended-position trigger provide maximum comfort and control
- Delivers fast working progress due to 0-1,300 rpm speed range

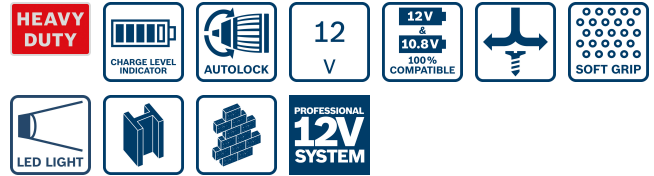

You can find more information about the deviations in the following link: <https://www.bosch-professional.com/mz/en/wac/>

