

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2119420003](#)
Status: **Active**
Overview: Coeur CST High-Current Interconnect System
Description: Coeur CST High-Current 6.00mm Receptacle Crimp Housing, Dual Row, 2 Circuits, Keying Option B, Blue

Documents:

Drawing (PDF)	Packaging Specification 2119420000-PK-000 (PDF)
Product Specification 2119410000-PS-000 (PDF)	Test Summary 2119410000-TS-000 (PDF)
Application Specification 2119410000-AS-000 (PDF)	RoHS Certificate of Compliance (PDF)

General

Product Family	Crimp Housings
Series	211942
Application	Power, Wire-to-Board
Overview	Coeur CST High-Current Interconnect System
Product Name	Coeur CST
UPC	191130961382


Physical

Circuits (maximum)	2
Color - Resin	Blue
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	Polyester
Net Weight	18.323/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	N/A
Pitch - Mating Interface	19.06mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-40° to +105°C

Material Info

Reference - Drawing Numbers

Application Specification	2119410000-AS-000
Packaging Specification	2119420000-PK-000
Product Specification	2119410000-PS-000
Sales Drawing	2119420000-SD-000
Test Summary	2119410000-TS-000

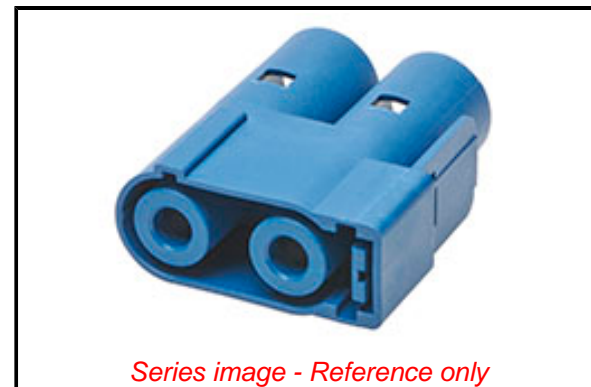

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ECHA_01_2020 (16
January 2020

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[211942](#) Series

Mates With

6.00mm Male Header [211937](#)

Use With

6.00mm Female Crimp Socket [204608](#)

 6.00mm Terminal Retention Housing
[211888](#)