


Technical data

NATR10

Roller follower with inner ring

Needle roller bearing, roller follower, with cage, with inner ring, spherical outer ring

VISUAL (S)

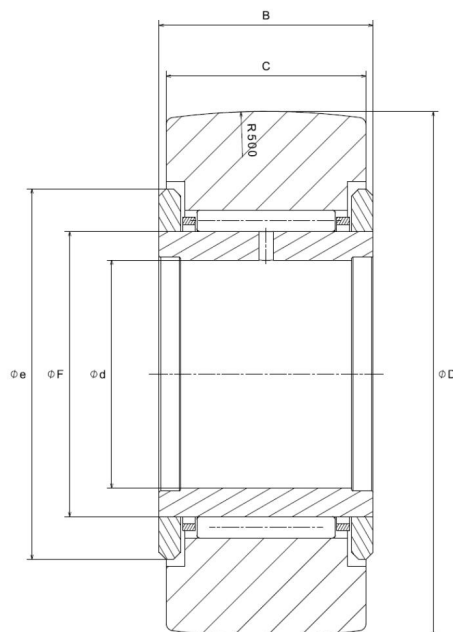

PRODUCT DEFINITION

Brand	NTN
d - Internal diameter	10 mm
D - External diameter	30 mm
C - Width of bearing, drawn cup or outer ring	14 mm
F - Under roller diameter	15 mm
B - Bearing/Inner ring width	15 mm
e - Inlet diameter of roller or washer	23 mm
R - Track roller radius	500 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

NATR10

Roller follower with inner ring

PRODUCT DEFINITION

Bearing with/without cage	Avec
Radial clearance class	CN
Precision class	P0
Mass	0,061 kg

PRODUCT PERFORMANCE

Cr - Dynamic load rating	7,85 kN
C0r - Static load rating	9,65 kN
Track load capacity spherical outer ring	2,62 kN
N lim - Grease lubrication limit speed	10000 tr/min
N lim - Oil lubrication limit speed	13000 tr/min
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	120 °C

ESHOPDONOTDISPLAY

Tracepart	Oui/Yes
Reference	NATR10
Image	NRBNATR_1.jpg, NRBNATR_3.jpg
Rolling element material	Acier 100Cr6



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15