


Features

- RS PRO 70 A crimp module.

RS PRO Industrial Power Connectors

RS Stock No.: 0457214, 0457215

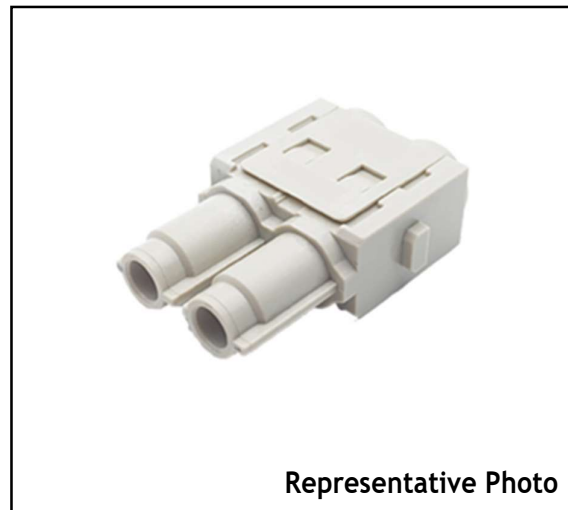

Representative Photo

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price

Product Description

- Inserts have a grounded contact to stop incorrect polarisation and contacts are mounted in the insert. This also means no additional tooling is required. The Inserts are available in the most popular sizes 6 PE, 10 PE, 16 PE, 24 PE, 32 PE and 48 PE.*

General Specifications

Flammability acc. to UL 94	V 0
Limiting temperature	-40 ... +125 °C
Mating cycles	□500
Material (insert)	Polycarbonate
Material (Contacts)	Copper alloy (Hard-Silver Plated)

Mechanical Specifications

Termination	Crimp terminal
Cable Entry	Back
No. of contact	2
Electrical Data	
acc. to EN 61984	70 A 1000 V 8 kV 3
Wire gauge	10-25 mm ²
Max. insulation diameter	11mm
Stripping length	15.5mm

Electrical Specifications

Insulation resistance	□10 ¹⁰ Ω
Contact Resistance	□0.5 mΩ

RS Pro 70 A Module 70 A 1000 V 8 kV 3	
Male insert (M) Part Number: 0457214	
Female insert (F) Part Number: 0457215	
	