

Datasheet

SPST Rocker Switch

RS Stock number 734-7365





SPECIFICATION

- 1、Electrical rating : DC 15V 5A[Ⓒ]
- 2、Contact resistance : <20mΩ(initial)
- 3、Insulation resistance : >1000MΩ(500VDC between open contacts)
- 4、Dielectric strength : >1500V 1 minute
- 5、Electrical life : 6000 cycles
- 6、Temperature rise at the terminal : Max.30℃
- 7、Solder ability of terminal : Max350℃,3S(no pressure may be placed in the terminals when soldering by hand)
- 8、Any Cd Pb Hg etc and it's compounds is not include in this product

PATENT NO. : M376887

Dimensions – inch mm

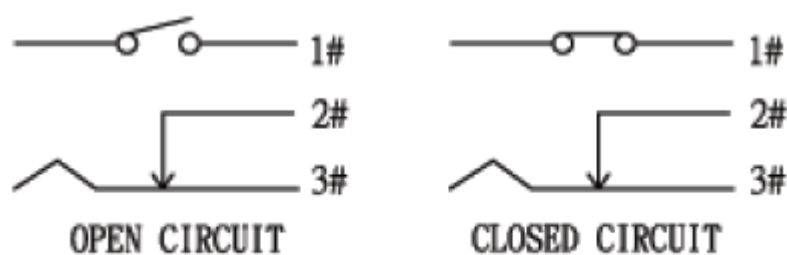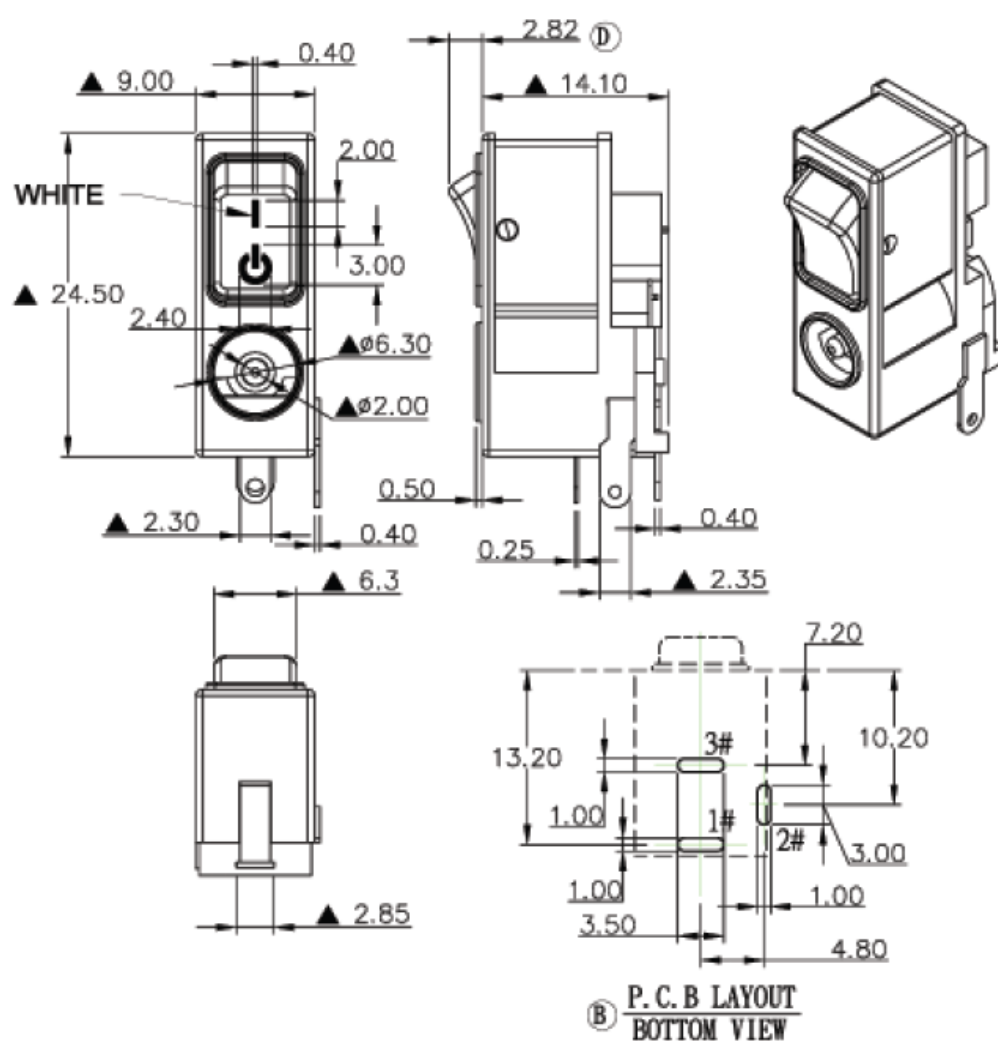

SCHEMATIC