


PRODUCT-DETAILS

## AMD121944-MG

### AMD121944-MG Switch 1-gang Intermediate, SP 10AX, Premium rocker size - MG

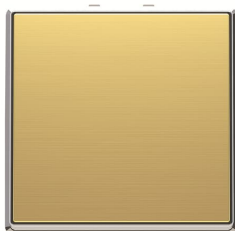

#### General Information

Extended Product Type	AMD121944-MG
Product ID	2CLA621000N1756
EAN	8427238096636
Catalog Description	AMD121944-MG Switch 1-gang Intermediate, SP 10AX, Premium rocker size - MG
Long Description	Rated voltage: 250Vac Rated current: 10AX Premium size rocker

#### Ordering

EAN	8427238096636
Customs Tariff Number	85365080
Minimum Order Quantity	10 piece

#### Dimensions

Product Net Depth / Length	0.122 m
Product Net Height	0.091 m
Product Net Width	0.116 m
Product Net Weight	0.042 kg

#### Container Information

Package Level 1 Units	10 piece
Package Level 1 EAN	8427238096636
Package Level 1 Depth / Length	0.122 m
Package Level 1 Height	0.091 m
Package Level 1 Width	0.116 m
Package Level 1 Gross Weight	0.42 kg

## Technical

Ambient Air Temperature	Operation -5 ... +35 °C Storage -5 ... +50 °C
Degree of Protection	IP20
Mounting Type	Flush mounted (plaster)

## Certificates and Declarations (Document Number)

Data Sheet, Technical Information	9AKK106930A7740
Declaration of Conformity - CE	No declaration needed
Instructions and Manuals	9AKK106930A7740

## Classifications

ETIM 7	EC001590 - Switch
ETIM 8	EC001590 - Installation switch
WEEE Category	5. Small Equipment (No External Dimension More Than 50 cm)

## Categories

Low Voltage Products and Systems → Switch Assortments → Flush Mounted Range BS - Niessen → Design Millenium → Flush Mounted Inserts with Cover Plate → Mechanical Switch / Push Button

Low Voltage Products and Systems → Switch Assortments → Light / LoadControl → Mechanical Switch / Push Button → Mechanical Switch / Push Button - Flush Mounted → Mechanical Switch / Push Button

