



fitted with
work equipment
connected load
power consumption
luminous flux
luminous efficacy
light distribution
light colour
color rendering index (CRI)
system of protection
class of protection
technology
usage
luminaire body
lamp cover
tubular sections
balance of articulation joints
weight (net)
mains lead
fastening

special features


3 x Light-emitting diode
 without
 24 V; AC/DC
 approx. 6 W
 approx. 460 lm
 approx. 77 lm/W
 direct
 daylight white, approx. 5700 K
 > 72
 IP 65
 III
 switchable
 switch
 aluminium, anodised, black
 glass screen
 steel tube, painted, Jet black
 friction
 approx. 1.3 kg
 approx. 3.0 m; with free stranded wires
 screw-down flange, magnetic base (accessory), table
 clamp (accessory), wall bracket (accessory)
 Flood with 40° angle of radiation



illuminance

Comment: d=50cm

Em: 3000 lx
 Emax: 5958 lx
 Emin: 721 lx

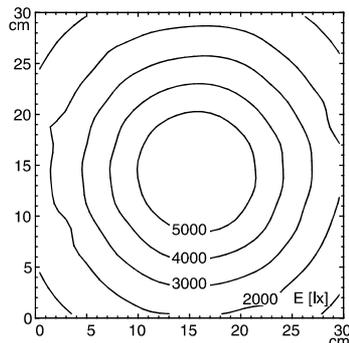

luminous intensity

