


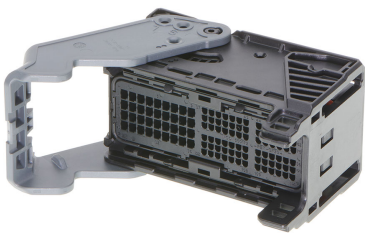

Part Number : [5601551402](#)
Product Description : Compactus CTX-J Sealed Connector, 114 Circuits, 78 x 0.50mm and 36 x 1.00mm Terminals, 0.50mm Side Wire Output
Series Number : 560155
Status : Active
Product Category : Connector Housings




Documents & Resources

Drawings
[5601551402_sd.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Duty-To-Declare
China RoHS	
EU ELV	Compliant per 2000/53/EC
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Connector Housings
Series	560155
Description	Compactus CTX-J Sealed Connector, 114 Circuits, 78 x 0.50mm and 36 x 1.00mm Terminals, 0.50mm Side Wire Output
Application	Automotive, Power, Wire-to-Board
Product Name	Compactus
UPC	191130088805

Physical

Circuits Detail	78 x 0.50mm, 36 x 1.00mm terminals
Circuits (maximum)	114
Color - Resin	Black
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	PBT
Net Weight	84.530/g
Number of Rows	6
Packaging Type	Tray
Panel Mount	No
Pitch - Mating Interface	2.45mm, 3.05mm
Stackable	No
Temperature Range - Operating	-40° to +120°C

Use with Part(s)

Description	Part Number
CTX-J50 Female Terminals	<u>560121</u>

CTX-J 100 Female Terminals	<u>560205</u>
CTX-J50 Dummy Plugs	<u>560144</u>
Compactus Dummy Plugs	<u>503131</u>
Compactus Wire Dress Covers	<u>560191</u>

This document was generated on Jan 17, 2025