


Features

- SC Connector
- OS2: IEC IEC 60793-2-40
- SC Connector: IEC 61754-4
- 900um

RS PRO Pigtail 9 OS2 900um Loose easy strip White SC/UPC

IL<0,25dB 1,00 m

RS Stock No.: 0794564

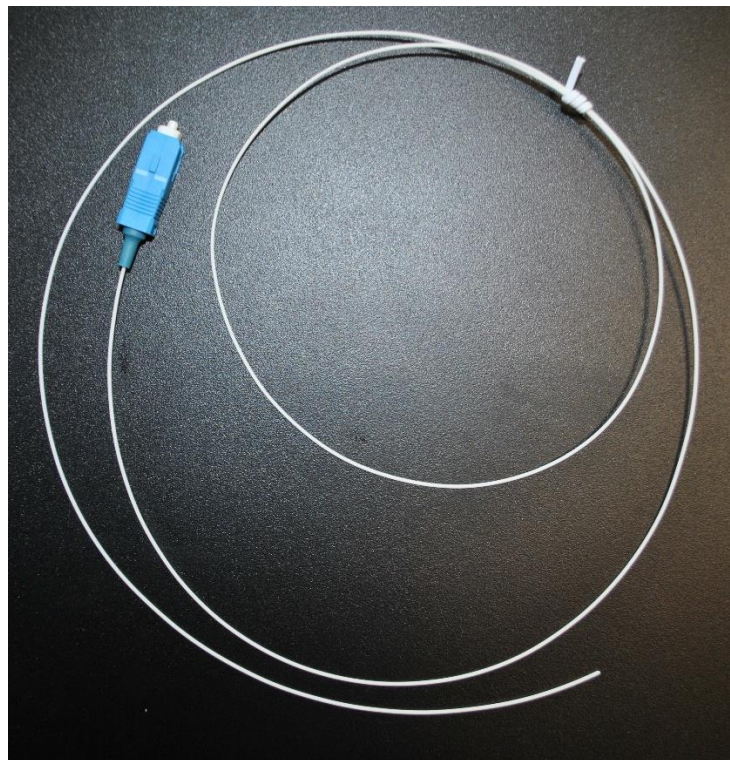

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

1 fiber optic pigtails are ideal for fusion splicing the required fiber connectivity for structured cabling systems including Data Centers, Broadband CATV, PON ,WDM or DWDM multiplexing, FTTH and voice services in ATM and SONET metropolitan and access networks. The OS2 bend insensitive fiber optic pigtails have less attenuation when bent or twisted compared with traditional fiber optic pigtails and this will make the installation and maintenance more efficient.

General Specifications

IL&RL TESTING	Compliant with IEC 61300-3-34
GEOMETRICAL CHARACTERISTICS	Compliant with IEC 61755-3-1
Connector End face	Compliant with IEC 61300-3-35

Technical Specifications

Connector Type	SC
Fiber	SM
Cable	900um LSZH Loose Tube
Jacket Color	1 color
Fiber Count	1 Fibers
Operating Temperature	20/70°C
Polish Type	UPC

Optical Specifications

Vibration	$\leq 0.2\text{dB}$
Insertion Loss	$\leq 0.25\text{dB}$
Return Loss	$\geq 50\text{dB}$
Durability	1000 Times

Approvals

Declarations	MFR Declaration of Conformity
Standards Met	RoHS Compliant REACH