


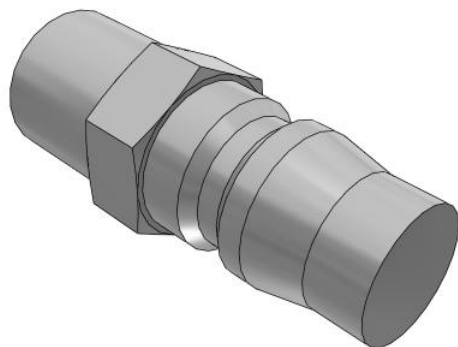

## KK130P-\*M, S-Couplers, Male Thread

### KK130P-02MS

Datasheet


### General series information

- Male thread.
- Applicable Port Size: R1/8, R1/4, R3/8, R1/2, NPT1/8, NPT1/4, NPT3/8, NPT1/2.

### Standard specifications

|                             |                                                                              |
|-----------------------------|------------------------------------------------------------------------------|
| Piping Port Size            | R 1/4                                                                        |
| Pressure medium             | Air                                                                          |
| Maximum operating pressure  | 1.5 MPa                                                                      |
| Minimum operating pressure  | 0 MPa                                                                        |
| Proof pressure              | 2 MPa                                                                        |
| Maximum ambient temperature | 80 °C                                                                        |
| Minimum ambient temperature | -20 °C (with no freezing)                                                    |
| Sealing principle           | Male thread with sealant                                                     |
| Plating                     | Sleeve: Electroless nickel plated Other external metal parts: Zinc chromated |
| Weight                      | 0.021 Kg                                                                     |

## Dimensions

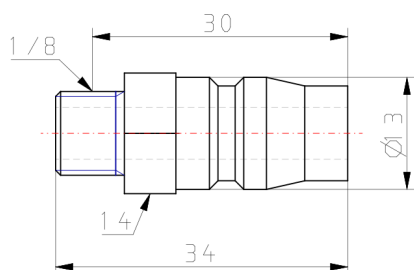

## Additional information

Catalogue

[KK130-B\\_EU.pdf](#)