

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0687890038](#)
Status: **Active**
Overview: [USB Products and Solutions](#)
Description: USB Shielded I/O Cable Assembly, USB 3.0, Type A Male-to-Type B Male, 1.0m Length, Black

Documents:

[3D Model](#) [Packaging Specification 687890035-PK \(PDF\)](#)
[3D Model \(PDF\)](#) [Packaging Specification 687890038-PK \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family [Cable Assemblies](#)
Series [68789](#)
Assembly Configuration [Dual Ended Connectors](#)
Connector to Connector [USB Type A-to-B](#)
Overview [USB Products and Solutions](#)
Product Name [USB](#)
UPC [191130109609](#)

Physical

Cable Length [1.0m](#)
Circuits (Loaded) [9](#)
Color - Resin [Black](#)
Gender [Male-Male](#)
Lock to Mating Part [Yes](#)
Net Weight [55.400/g](#)
Number of Rows [2, 3](#)
Packaging Type [Bag](#)
Single Ended [No](#)
Wire/Cable Type [PVC](#)


Electrical

Current - Maximum per Contact [0.9A](#)
Shielded [Yes](#)
Voltage - Maximum [30V AC](#)

Material Info

Reference - Drawing Numbers

Packaging Specification [687890035-PK, 687890038-PK](#)
Sales Drawing [2012410607-000](#)

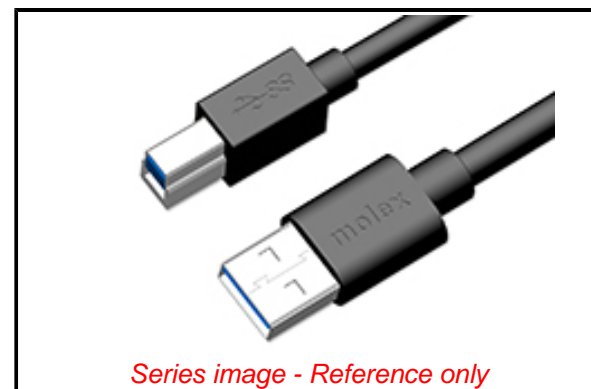

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)4578-DC (25
June 2020)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Compliant

Not Contained

Search Parts in this Series

[68789 Series](#)