

HIGH SPEED DRILLING IN WOOD

EXPERT Self Cut Speed Spade Drill Bit

EXPERT

- ① Fast drilling is easier with Bosch Tip Technology
- ② Self-feeding thread for high-speed drilling with only a little pressure
- ③ Clever wave-shaped spade designed for fast chip removal




TIP
TECHNOLOGY

UP TO
3x*



* vs. Bosch Spade Bit 2609255269

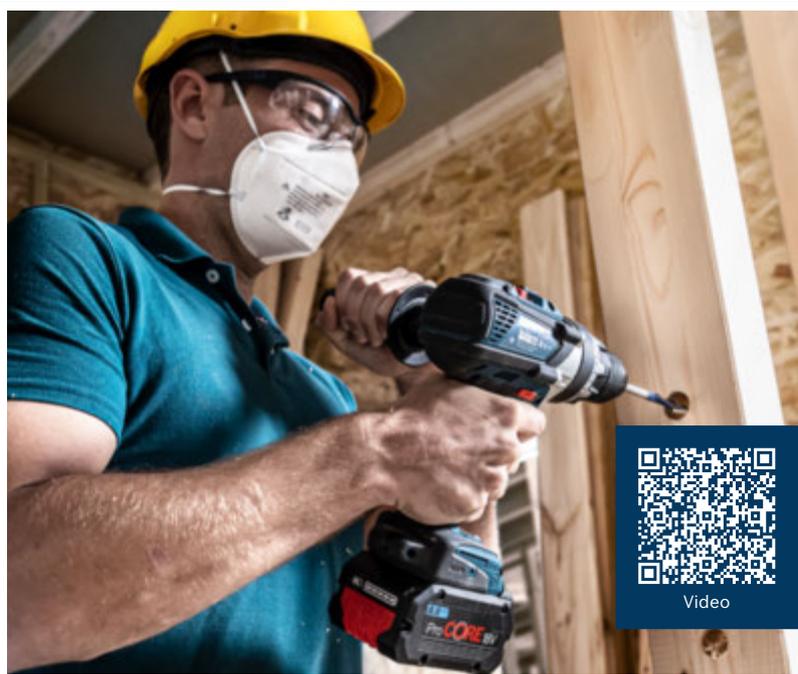

BOSCH

EXPERT SELF CUT SPEED SPADE DRILL BIT



- ▶ Ideal for fast and rough drilling in all types of softwood, such as drilling through holes for cables, pipes, and other hardware installations. Easy to use in tight niches. Not suitable for hardwood
- ▶ Best for electricians and other installation workers: high speed and efficiency
- ▶ Up to 3x faster than Bosch 2609255269 Spade Bit
- ▶ 1/4" Impact rated Hex shank for use in impact driver and drill driver



PRODUCT PROPERTIES					ORDERING INFORMATION				
Diameter (D) mm	Working length mm	Total length mm	Shank diameter (d) mm	Shank diameter (d) Inch	Packaging type	Pack quantity	Minimum order quantity	Barcode 4 059 952...	Part number
Total length 152 mm									
6.00	100	152	6.35	1/4	PC1d	1	5	533 834	2 608 900 309
Total length 400 mm									
6.00	350	406	6.35	1/4	PC1a	1	5	534 114	2 608 900 337
Total length 152 mm									
8.00	100	152	6.35	1/4	PC1d	1	5	533 841	2 608 900 310
Total length 400 mm									
8.00	350	406	6.35	1/4	PC1a	1	5	534 121	2 608 900 338
Total length 152 mm									
10.00	100	152	6.35	1/4	PC1d	1	5	533 858	2 608 900 311
Total length 400 mm									
10.00	350	406	6.35	1/4	PC1a	1	5	534 138	2 608 900 339
Total length 152 mm									
12.00	100	152	6.35	1/4	PC1d	1	5	533 865	2 608 900 312
Total length 400 mm									
12.00	350	406	6.35	1/4	PC1a	1	5	534 145	2 608 900 340
Total length 152 mm									
13.00	100	152	6.35	1/4	PC1d	1	5	533 872	2 608 900 313
Total length 400 mm									
13.00	350	406	6.35	1/4	PC1a	1	5	534 152	2 608 900 341
Total length 152 mm									
14.00	100	152	6.35	1/4	PC1d	1	5	533 889	2 608 900 314
Total length 400 mm									
14.00	350	406	6.35	1/4	PC1a	1	5	534 169	2 608 900 342
Total length 152 mm									
16.00	100	152	6.35	1/4	PC1d	1	5	533 896	2 608 900 315
Total length 400 mm									
16.00	350	406	6.35	1/4	PC1a	1	5	534 176	2 608 900 343
Total length 152 mm									
17.00	100	152	6.35	1/4	PC1d	1	5	533 902	2 608 900 316
Total length 400 mm									



BOSCH

EXPERT SELF CUT SPEED SPADE DRILL BIT

PRODUCT PROPERTIES					ORDERING INFORMATION				
Diameter (D) mm	Working length mm	Total length mm	Shank diameter (d) mm	Shank diameter (d) Inch	Packaging type	Pack quantity	Minimum order quantity	Barcode 4 059 952...	Part number
17.00	350	406	6.35	1/4	PC1a	1	5	534 183	2 608 900 344
Total length 152 mm									
18.00	100	152	6.35	1/4	PC1d	1	5	533 919	2 608 900 317
Total length 400 mm									
18.00	350	406	6.35	1/4	PC1a	1	5	534 190	2 608 900 345
Total length 152 mm									
19.00	100	152	6.35	1/4	PC1d	1	5	533 926	2 608 900 318
Total length 400 mm									
19.00	350	406	6.35	1/4	PC1a	1	5	534 206	2 608 900 346
Total length 152 mm									
20.00	100	152	6.35	1/4	PC1d	1	5	533 933	2 608 900 319
Total length 400 mm									
20.00	350	406	6.35	1/4	PC1a	1	5	534 213	2 608 900 347
Total length 152 mm									
22.00	100	152	6.35	1/4	PC1d	1	5	533 940	2 608 900 320
Total length 400 mm									
22.00	350	406	6.35	1/4	PC1a	1	5	534 220	2 608 900 348
Total length 152 mm									
24.00	100	152	6.35	1/4	PC1d	1	5	533 957	2 608 900 321
Total length 400 mm									
24.00	350	406	6.35	1/4	PC1a	1	5	534 237	2 608 900 349
Total length 152 mm									
25.00	100	152	6.35	1/4	PC1d	1	5	533 964	2 608 900 322
Total length 400 mm									
25.00	350	406	6.35	1/4	PC1a	1	5	534 244	2 608 900 350
Total length 152 mm									
26.00	100	152	6.35	1/4	PC1d	1	5	533 971	2 608 900 323
Total length 400 mm									
26.00	350	406	6.35	1/4	PC1a	1	5	534 251	2 608 900 351
Total length 152 mm									
28.00	100	152	6.35	1/4	PC1d	1	5	533 988	2 608 900 324
Total length 400 mm									
28.00	350	406	6.35	1/4	PC1a	1	5	534 268	2 608 900 352
Total length 152 mm									
30.00	100	152	6.35	1/4	PC1d	1	5	533 995	2 608 900 325
Total length 400 mm									
30.00	350	406	6.35	1/4	PC1a	1	5	534 275	2 608 900 353
Total length 152 mm									
32.00	100	152	6.35	1/4	PC1d	1	5	534 008	2 608 900 326
Total length 400 mm									
32.00	350	406	6.35	1/4	PC1a	1	5	534 282	2 608 900 354
Total length 152 mm									
35.00	100	152	6.35	1/4	PC1d	1	5	534 015	2 608 900 327



BOSCH

EXPERT SELF CUT SPEED SPADE DRILL BIT

PRODUCT PROPERTIES					ORDERING INFORMATION				
Diameter (D) mm	Working length mm	Total length mm	Shank diameter (d) mm	Shank diameter (d) Inch	Packaging type	Pack quantity	Minimum order quantity	Barcode 4 059 952...	Part number
Total length 400 mm									
35.00	350	406	6.35	1/4	PC1a	1	5	534 299	2 608 900 355
Total length 152 mm									
36.00	100	152	6.35	1/4	PC1d	1	5	534 022	2 608 900 328
Total length 400 mm									
36.00	350	406	6.35	1/4	PC1a	1	5	534 305	2 608 900 356
Total length 152 mm									
38.00	100	152	6.35	1/4	PC1d	1	5	534 039	2 608 900 329
Total length 400 mm									
38.00	350	406	6.35	1/4	PC1a	1	5	534 312	2 608 900 357
Total length 152 mm									
40.00	100	152	6.35	1/4	PC1d	1	5	534 046	2 608 900 330
Total length 400 mm									
40.00	350	406	6.35	1/4	PC1a	1	5	534 329	2 608 900 358



BOSCH