

Previously known as: MICROGARD® 2000 Overboots - Model 406

Safety overboots offering superior breathable microporous laminate technology.

- **Improved defenses:** AlphaTec® 2000 STANDARD Overboots Bound - Model 406 grants a proven protective barrier to low-concentration liquid chemicals, liquid and particulate biological hazards
- **Augmented protection:** Comfortable to wear, these protective overshoes are composed of moisture vapor permeable fabric, which reduces the risk of heat stress
- **Enhanced ergonomics:** Beyond providing chemical resistance, these overboots afford an optimized fit, which guarantees comfort and safety
- **Reduced contamination risks:** In addition, these low-linting overboots are ideal for controlled environments as they reduce contamination risks



Industries

- Life Sciences
- Metal fabrication
- Food Processing


Applications

- Clean room cleaning and preparing
- Production line support & maintenance
- Maintenance of plant and machines
- Veterinary Services
- Body painting including surface inspection
- Cleaning of plant and machines


KEY FEATURES & BENEFITS

- **Protective barrier:** Reliable personal protection from chemicals
- **Moisture vapor permeable fabric:** Reduced heat stress risk
- **Optimized fit:** For form-fitting footwear combining comfort and safety

Material Diagram

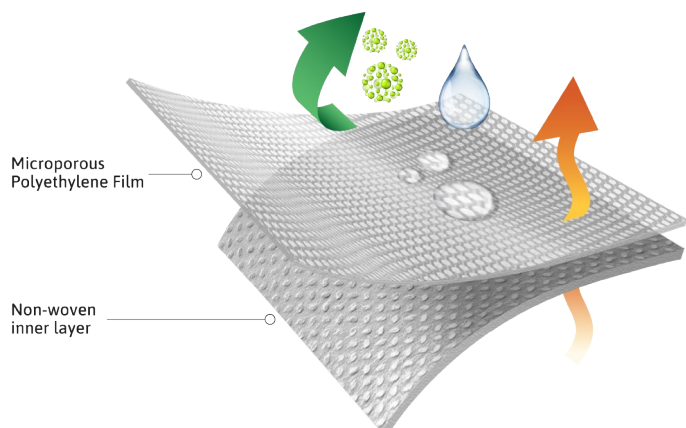

Seam Diagram

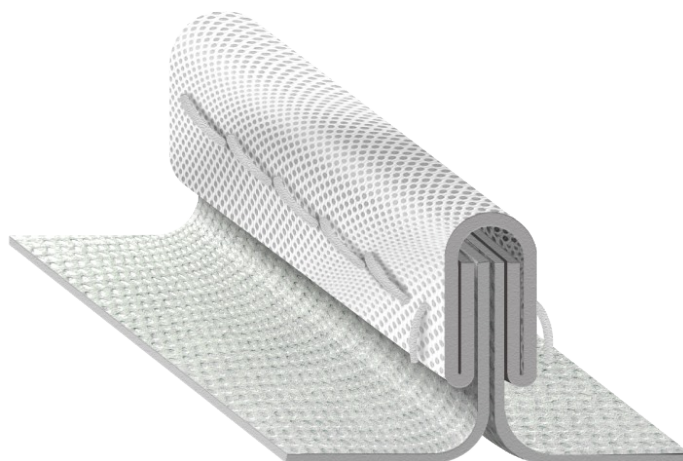

Performance Standards


0598


PARTIAL BODY
PROTECTION ONLY


TYPE PB [6]


EN 14126

EN ISO 13688:2013

Product Information

Product Information	
Available Sizes	One Size
Color	White
Country Of Origin	China, Sri Lanka
Packaging Overview	50 pairs every compressed bag
Product Material	Microporous polyethylene Laminate non-woven
Product Reference	AlphaTec 2000 STANDARD Overboots Bound Models 406
Standards Overview	CE CATEGORY III (Type PB (6)-B, EN 14126)
Seam Type	Bound
Shelf Life	5 years
Style Number	W20B406

Suit components & accessories

Suit Components and Accessories	
Design Features	Tie fastening, elastic to top of boot & bound seams

For additional information visit us at www.ansell.com, or call us at

Europe, Middle East & Africa Region
Ansell Healthcare Europe NV
T: +32 (0) 2 528 74 00

North America Region
Ansell Healthcare Products LLC
T: +1 800 800 0444

Australia
Ansell Limited
T: +61 1800 337 041

Asia Pacific Region
Ansell Global Trading Center
T: +603 8310 6688

Latin America & Caribbean Region
Ansell Commercial Mexico S.A. de C.V.
T: +52 442 248 1544 / 248 3133

Ansell, ® and ™ are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending: www.ansell.com/patentmarking © 2025 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.

