


# Drive shaft adapter EAMB-34-6-25X26-23X27

Part number: 558037

FESTO

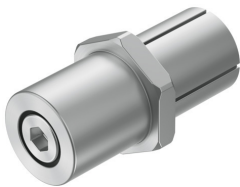

 [General operating condition](#)

## Data sheet

| Feature                | Value                  |
|------------------------|------------------------|
| Mounting diameter 1    | 25 mm                  |
| Mounting diameter 2    | 23 mm                  |
| Size                   | 120                    |
| Nominal length         | 26 mm                  |
| Mounting position      | optional               |
| Max. rotational speed  | 5500 rpm               |
| LABS (PWIS) conformity | VDMA24364-B2-L         |
| Storage temperature    | -25 °C ... 60 °C       |
| Relative air humidity  | 0 - 95%                |
| Ambient temperature    | -25 °C ... 60 °C       |
| Mass moment of inertia | 18.2 kgmm <sup>2</sup> |
| Transmittable torque   | 100 Nm                 |
| Product weight         | 201 g                  |
| Note on materials      | RoHS-compliant         |