

## Datasheet

### **RS Pro V9371 7W Lighting Controller Switch, Daylight, Wall mount, 250 V**

RS Stock No: **743-886**



## Product Details

RS Pro V9371 7 W lighting controller switch has a current rating of 10 A and voltage rating of 250 V. This wall mount controller automatically turn lights on/off in response to changes in ambient light levels, primarily the transition from day to night and vice versa. The sensor is designed such that four thresholds are actually monitored namely dusk, the middle of the night, dawn and the middle of the day.


## Features and Benefits

- Rotating front cover sets lux level required
- Time delay prevents intermittent switching
- LED indication of unit operation
- Sensor type photocell resistor
- Temperature range of -30C to +65C
- Setting range 5 to 100 Lux
- Switching current at 250 V ac 10 A
- Switch delay approx 0 to 20 seconds
- IP54 rated

## Specifications:

Controller Type	Switch
Current Rating	10 A
Diameter	130 mm
Height	50 mm
Mount Type	Wall
Power Consumption	7 W
Range	Adjustable
Sensor Type	Daylight
Time Delay	0 to 20 s
Voltage Rating	250 V

### Abmessungen | Dimensions

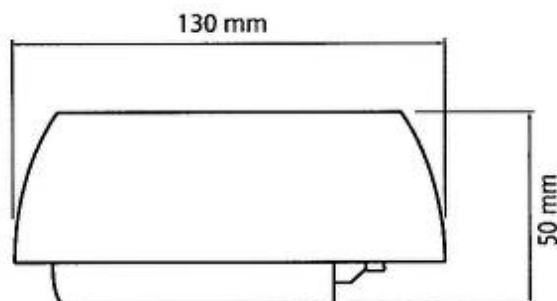

### Schaltbild | Wiring diagram

