

FEATURES

- Provides effortless connection for sensor & actuator cables
- IP67
- 60 V rated voltage

RS PRO M12 MALE 4 PIN TO M08 FEMALE 4 PIN ADAPTOR

RS Stock No.: 2080544



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

ATTRIBUTE 1

M12 to M8 Straight Adapters

Adapters from RS PRO are a range of M8 to M12, or M12 to M8 adapters that are perfect for either permanent solutions or quick, field connections. They're a standard coding 'A' and come backed by an excellent IP67 rating when mated with other connectors

Features and Benefits:

- Provides effortless connection for sensor & actuator cables
- IP67
- 60 V rated voltage

General Specifications

Rated Operational Voltage	30 V
Current Rating	4A
Insulation Resistance	>= 100 MΩ
Temperature Range	-25°C ... +75°C
Coding	A-Coded
Degree of pollution	3
Matting Cycles	>100

Material Specifications

Contact	Cu-Zn
Contact Plating	Gold Flash
Contact Carrier	Nylon 66
O-Ring	Neoprene
Housing	Nickel Plated Brass
Pole	4
Coupling Nut	Nickel Plated Brass

Protection Category

Degree of Protection	IP67
----------------------	------

Additional Information

Custom Tariff Number: 85369090


Approvals

Standards Met: IEC 61076-2-101 (M12), IEC 61076-2-104 (M08)

Similar Products

Stock No.	Brand	Product Name	Attribute 1	Attribute 2
-	-	-	-	-

Connection Diagrams / Assembly Diagrams / Illustrations / Accessories

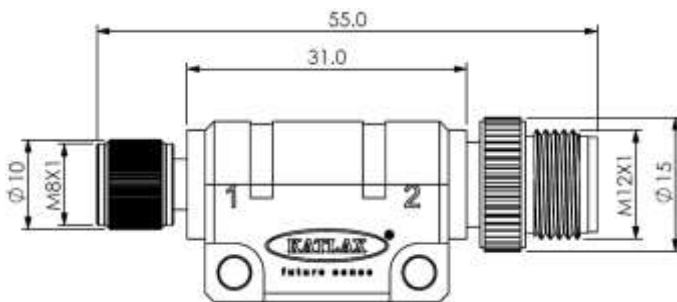

All Dimensions are in mm.

