

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

**Part Number:** [19069-0230](#)  
**Status:** **Active**  
**Overview:** [Solderless Terminals](#)  
**Description:** Krimptite™ Ring Tongue Terminal for 10-12 AWG Wire, Stud Size 6 (M3.5), Length 18.82mm

**Documents:**

[Drawing \(PDF\)](#) [Product Specification PS-19902-013 \(PDF\)](#)  
[Product Specification PS-19902-011 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR18689  
UL E32244

**General**

Product Family Ring and Spade Terminals  
Series [19069](#)  
Crimp Quality Equipment Yes  
Mil-Spec N/A  
Overview [Solderless Terminals](#)  
Product Name Krimptite™  
Type Ring  
UPC 800755067415

**Physical**

Barrel Type Closed  
Insulation None  
Material - Plating Mating Tin  
Material - Plating Termination Tin  
Net Weight 1.379/g  
Packaging Type Bag  
Plating min - Mating 2.540µm  
Plating min - Termination 2.540µm  
Stud Size 6 (M3.5)  
Termination Interface: Style Crimp or Compression  
Wire Size AWG 10, 12  
Wire Size mm² 4.00 - 6.00

**Material Info**

Old Part Number C-136-06

**Reference - Drawing Numbers**

Product Specification PS-19902-011, PS-19902-013  
Sales Drawing CCD10101

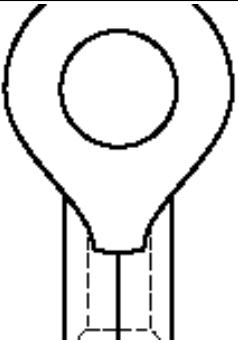


image - Reference only

Series

**EU RoHS**

**ELV and RoHS  
Compliant**

**REACH SVHC**

Not Reviewed

**Low-Halogen Status**

**Low-Halogen**

**China RoHS**



**Need more information on product  
environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
For a multiple part number RoHS Certificate of  
Compliance, [click here](#)

Please visit the [Contact Us](#) section for any  
non-product compliance questions.

**Search Parts in this Series**

[19069Series](#)

**Application Tooling | FAQ**

*Tooling specifications and manuals are  
found by selecting the products below.  
Crimp Height Specifications are then  
contained in the Application Tooling  
Specification document.*

**Global**

| Description        | Product #                  |
|--------------------|----------------------------|
| PremiumGrade™      | <a href="#">0640030100</a> |
| Hand Crimp Tool    |                            |
| Crimp Head for the | <a href="#">0640070100</a> |
| AT-200™ Pneumatic  |                            |
| Hand Tool          |                            |