



Highlights

- OS: Android 10
- Screen size: 10.1 inch
- Brightness: 250cd/m2
- Color: Black
- Power input: POE+ or External DC


LOOP meeting room panel

10.1 inch

- Find a free meeting room immediately via color indication
- Easy room management for meeting spaces
- No more ghost meetings with meeting confirmation timers
- Office 365 & Google Calendar integration
- Book meetings on the fly
- In room issues report from panel fast and easy
- Ask for services when booking the room such as catering or cleaning
- Digital signage platform integration
- Alarm system integration

Art.No. **7-961101**

GTIN **8713797106283**

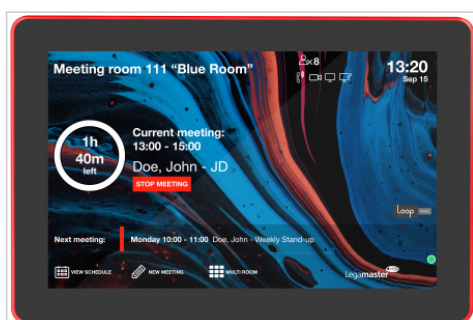

Article data sheet



Specifications

Article dimensions	259 x 178 x 28 mm
Colour	Black
Housing material	Plastic
Number of speakers	2
Aspect ratio	16:10
Contrast ratio	800:1
Display brightness	250 cd/m ²
Display diagonal	10.1 inch
Display resolution	1280 x 800
Display technology	LCD
Viewing angle	H: 85° / V: 85°
Mounting type	In wall
VESA mounting	Yes
VESA mounting interface	75 x 75
Ethernet LAN	Yes
Ethernet standards	100BASE-T, 1000BASE-T
Wi-Fi	Yes
Wi-Fi standards	802.11b, 802.11g, Wi-Fi 4 (802.11n)
Power supply type	DC/POE+
RJ-45 ports quantity	1
USB ports	2x USB 2.0 Type-A, 1x Micro USB 2.0 Type-A
CPU	Arm Cortex-A17 RK3288
Operating system	Android 10
Memory size	2 GB
Storage size	16 GB
Screen orientation	Landscape, Portrait
Product warranty	2 years
Number of touch points	10
Touchscreen technology	Capacitive
Operating temperature	0 °C - 40 °C
Package contents	License, Mounting instruction, Mounting material, Power supply unit, Quick setup guide, Wall mount kit

Logistics

GTIN	8713797106283
Article number	7-961101
Customs tariff number	847141000050
Quantity	1 piece
Packing dimensions	200 x 80 x 300 mm
Weight (gross/net)	1.60 kg / 1.00 kg

Article data sheet

Product overview

Article name	Article number	GTIN/EAN	Minimum order quantity
Legamaster LOOP meeting room panel 10.1 inch	7-961101	8713797106283	1