


562599



Shovel, Metal Detectable, D
Grip, 327 x 271 x 50 mm,
1040 mm, Dark blue

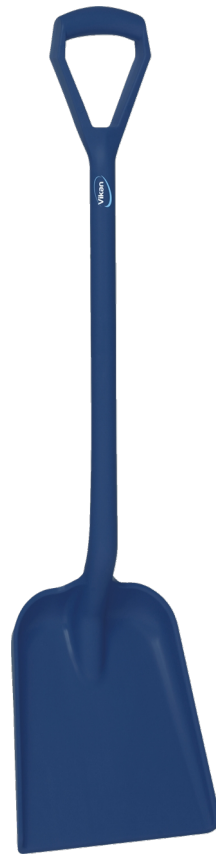

Lightweight and durable, this Metal Detectable Shovel features a one-piece construction that eliminates areas where bacteria can gather. Its smooth surface allows for easy cleaning, which makes it ideal for moving food ingredients or large quantities of food waste. Metal detectability enables use in production on food-contact surfaces. Can be tested using test kit (11199).

Technical Data

Item Number	562599
Shovel Blade Size, L x W x H	327 x 271 x 50 mm
Material	Polypropylene
Complies with (EC) 1935/2004 on food contact materials¹	Yes
Produced according to EU Regulation 2023/2006/EC of Good Manufacturing Practice	Yes
FDA compliant raw material (CFR 21)	Yes
Meets the REACH Regulation (EC) No. 1907/2006	Yes
Use of Phthalates	Yes
Is Halal compliant	Yes
Box Quantity	5 Pcs.
Quantity per Pallet (80 x 120 x 200 cm)	75 Pcs.
Quantity Per Layer (Pallet)	80 Pcs.
Box Length	1180 mm
Box Width	260 mm
Box Height	370 mm
Length/Depth	1040 mm
Width	271 mm
Height	120 mm
Gross Weight	1,82 kg
Net Weight	1,4 kg
Cubik metre	0,1135 M3
Recommended sterilisation temperature (Autoclave)	121 °C
Max. cleaning temperature (Dishwasher)	93 °C
Min. pH-value in usage concentration	2 pH
Max. pH-value in Usage Concentration	10,5 pH
GTIN-13 Number	5705025625997
GTIN-14 Number (Box quantity)	15705025625994
Commodity Code	96039099
Country of origin	Denmark

New equipment should be cleaned, disinfected, sterilised and any labels removed, as appropriate to its intended use, e.g. high risk vs. low risk food production areas, general hospital areas vs. intensive care units, before use.

3. Do not store the product below 0° Celsius.