

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

19003-0068

Status:

Active

Overview:

Quick-Disconnect Terminals

Description:

InsulKrimp™ Quick Disconnect, Female, for 24-26 (0.20-0.12mm²), Box, Tab 4.75 x 0.81mm

- Documents:
- 3D Model

Product Specification PS-19902-011 (PDF)
- Drawing (PDF)

Product Specification PS-19902-013 (PDF)
- Product Specification PS-19902-008 (PDF)

RoHS Certificate of Compliance (PDF)

General

Product Family

Quick Disconnects

Series

19003

Comments

Funnel Entry

Crimp Quality Equipment

Yes

Insulated

Fully

Overview

Quick-Disconnect Terminals

Product Name

InsulKrimp™

Type

Quick Disconnect

UPC

800754884006

Physical

Barrel Type

Closed

Color - Resin

Yellow

Gender

Female

Glow-Wire Compliant

Yes

Insulation

Nylon (PA)

Lock to Mating Part

None

Material - Metal

Brass

Material - Plating Mating

Tin

Material - Plating Termination

Tin

Material - Resin

Nylon

Net Weight

0.726/g

Orientation

Straight

Packaging Type

Bag

Plating min - Mating

4.064µm

Plating min - Termination

4.064µm

Polarized to Mating Part

No

Tab Thickness

0.81mm

Tab Width

4.75mm

Temperature Range - Operating

-65°C to +105°C

Termination Interface: Style

Crimp or Compression

Wire Insulation Diameter

1.90mm max.

Wire Size AWG

24, 26

Wire Size mm²

0.12 - 0.20

Electrical

Voltage - Maximum

600V

Material Info

Old Part Number

M-2211

Reference - Drawing Numbers

Product Specification

PS-19902-008, PS-19902-011, PS-19902-013

Sales Drawing

SD-19003-005

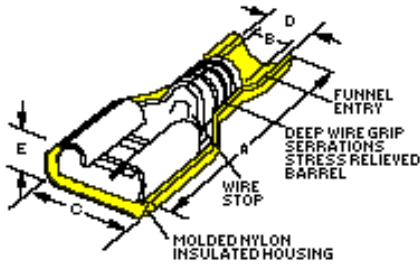


image - Reference only

Series

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Contains SVHC: Yes

China RoHS



Hydrazine
Dibutyl phthalate
Diarsenic pentaoxide
Diarsenic trioxide
Bis (2-ethyl(hexyl)phthalate) (DEHP)
Triethyl arsenate
Benzyl butyl phthalate
2-Pyrrolidinone, 1-methyl
2,4-Dinitrotoluene
Trixylyl phosphate
Sodium perborate; perboric acid, sodium salt
Sodium peroxometaborate

Low-Halogen Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

19003Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below.
Crimp Height Specifications are then

<i>contained in the Application Tooling Specification document.</i>	
Global	
Description	Product #
Hand Crimp Tool	<u>0640015200</u>
Crimp Head for the	<u>0640055200</u>
AT-200™ Pneumatic	
Hand Tool	

This document was generated on 10/15/2014

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION