




EMI & EMC Solutions > EMI Filters > Power Line Filters > 3-Phase Filters > 3 Phase Power Line Filters, Corcom APS Series

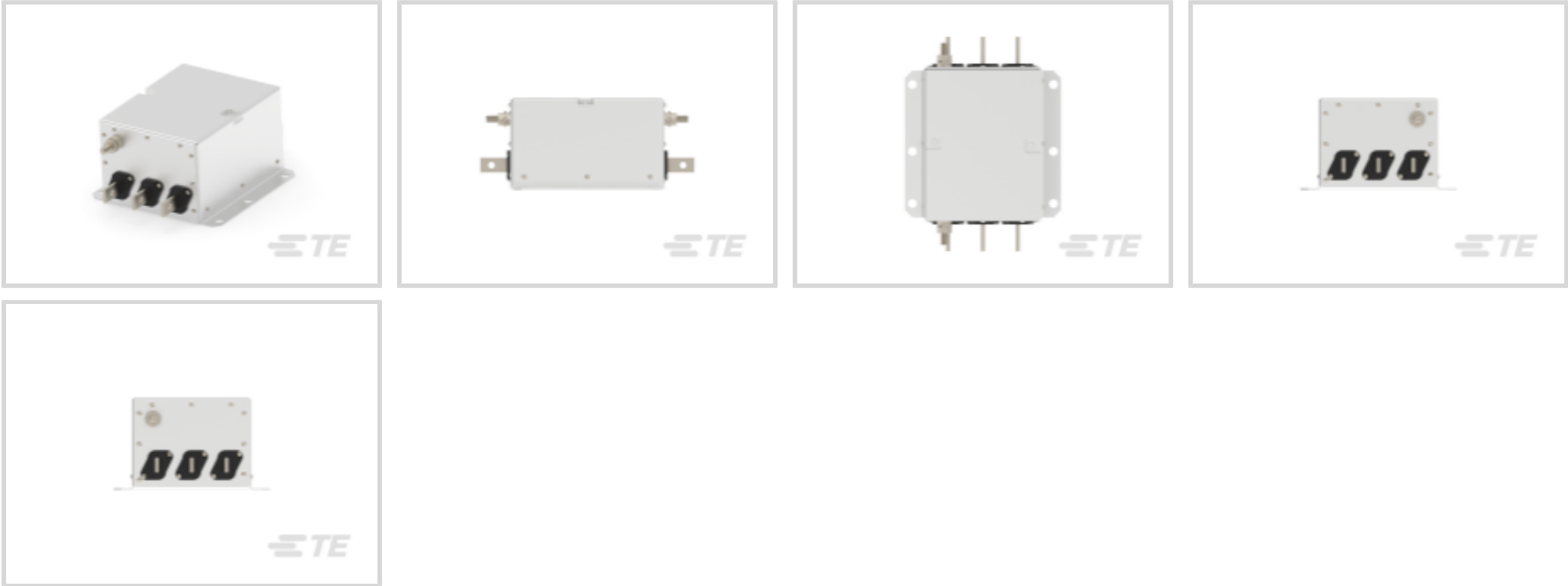

Current Rating: 250 A

Input Termination Type: Busbar

Output Termination Type: Busbar

Wiring Configuration: DELTA (3 wire + ground)

Operating Voltage: 520 VAC

All 3 Phase Power Line Filters, Corcom APS Series (10)

Features

Product Type Features

Filtering Requirements	Filtered
Input Termination Type	Busbar
Output Termination Type	Busbar

Configuration Features

Wiring Configuration	DELTA (3 wire + ground)
----------------------	-------------------------

Electrical Characteristics

Leakage Current (Max) (250VAC, 50Hz)	270 mA
Current Rating	250 A
Operating Voltage	520 VAC

Mechanical Attachment

Product Mount Type	Chassis Mount
--------------------	---------------

Usage Conditions

Operating Temperature Range	-10 – 50 °C
-----------------------------	-------------



Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts




TE Part # CAT-C8114-AP71
3 Phase Power Line Filters, Corcom APS Series



TE Part # 8-1609148-2
250APH12L=F8395

Also in the Series | Corcom APS

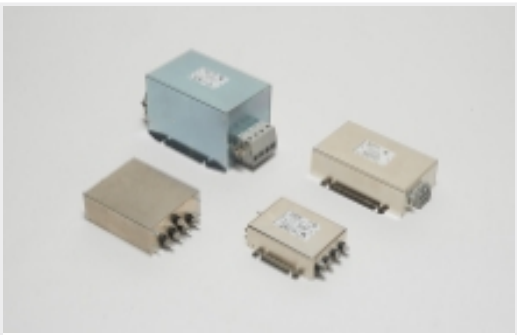

3-Phase Filters(10)


Customers Also Bought



TE Part #5-2176349-8
CRGCQ 2512 560K 1%



TE Part #7-1879352-0
RR02 5% 240R AMMO

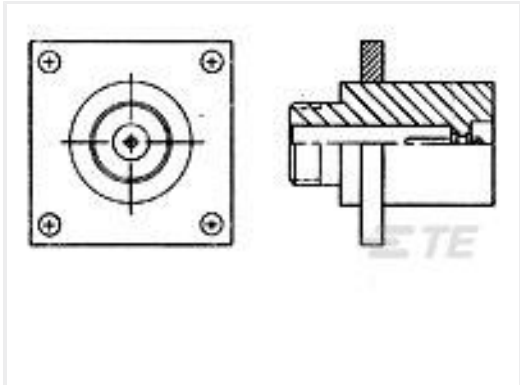

TE Part #850912-1
LGH-4 FLANGED RECEPT.



TE Part #5-1879353-7
RR02 5% 910K AMMO



TE Part #3-5435668-5
DIP SW 5 POSN W/TAPE AU




TE Part #6609070-8
110FCD10B =F7763



TE Part #32189
TERMINAL,DG R 16-14 4



TE Part #BKA186M27420100000
923 EXTENSION, SPEEDTEC

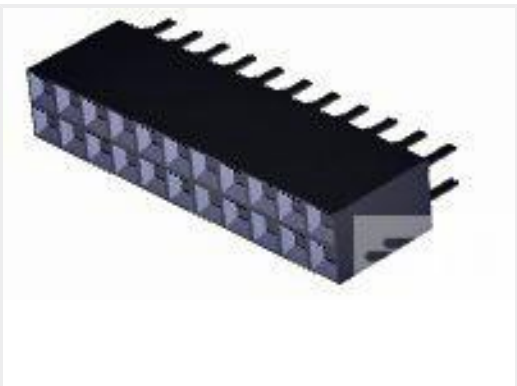

TE Part #1-534998-1
22 MODIV VRT DR CE 100/125



TE Part #8-1415013-1
MT323250

Documents

Product Drawings
250APS12L=F8409

English

CAD Files
Customer View Model
ENG_CVM_CVM_4-1609114-4_B.3d_igs.zip

English

Customer View Model

4-1609114-4

250 A 3-Phase Filter, Busbar Input, Busbar Output, DELTA (3 wire + ground), 520 VAC, Chassis Mount, Corcom APS



[ENG_CVM_CVM_4-1609114-4_B.3d_stp.zip](#)

English

Customer View Model

[ENG_CVM_CVM_4-1609114-4_B.2d_dxf.zip](#)

English

3D PDF

3D

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[Corcom APH/APS Series 3-phase high current EMI filters](#)

English

[Corcom Combined Selector Charts](#)

English