





| | |
|------------------------------|----------------------------------------|
| Order Code | TCK-044 |
| Inductance | 3.3 μ H \pm 20% (at 1 kHz / 1 V) |
| Impedance (DCR) | 60 mOhm max. |
| Rated Current | 2 A max. |
| Operating Temperature | -40°C to +125°C |

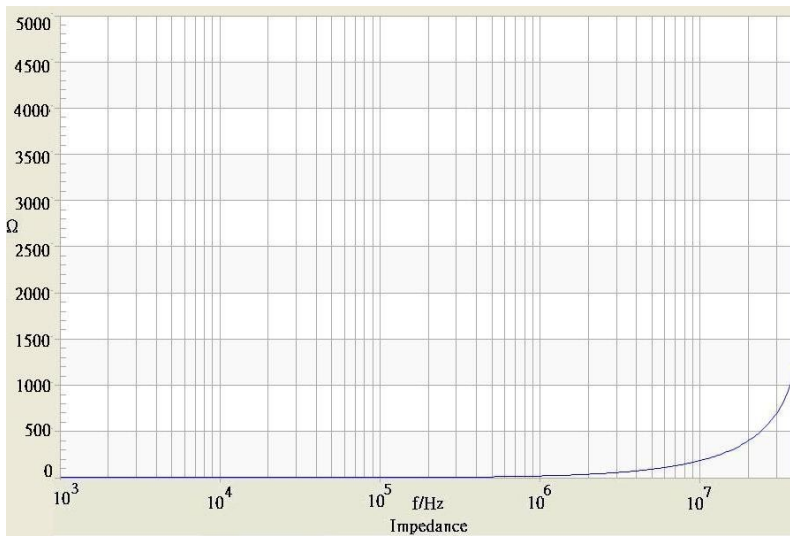

Impedance Curve



Outline Dimensions

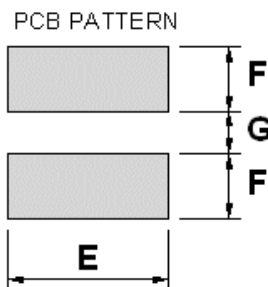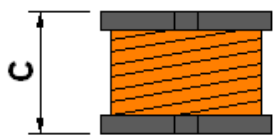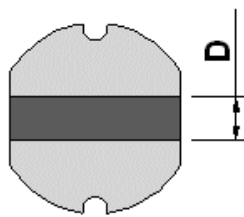

Dimensions [mm]

| | |
|----------|---------------|
| A | 5.2 \pm 0.5 |
| B | 5.8 \pm 0.5 |
| C | 5.2 max. |
| D | 1.3 typ. |
| E | 5.5 |
| F | 2.15 |
| G | 1.7 |