

**Buchsen <sup>1)</sup>**

Ø 0,5mm – Ø 1,57mm


**Sockets <sup>1)</sup>**

Ø 0,5 mm – Ø 1,57 mm

**Douilles <sup>1)</sup>**

Ø 0,5 mm – Ø 1,57 mm

1:1 

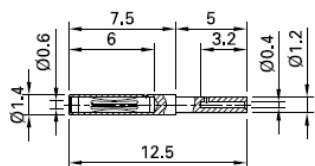

Typ Type Type	Bestell-Nr. Order No. No. de Cde	Nenn-Ø Nominal-Ø Ø nominal	Anschlussvariante Type of termination Type de raccordement	Sandwichbauweise Sandwich board construction Construction étagée possible	Metallteile / Oberfläche Metal parts / plating Partie métallique / traitement	Auszugskraft Withdrawal force Effort de débrochage	Bemessungsstrom <sup>2)</sup> Rated current <sup>2)</sup> Intensité assignée <sup>2)</sup>	Kontaktwiderstand Contact resistance Résistance de contact
		mm				N	A	mΩ
<b>B0,5</b>	<b>41.0056</b>	0,5	② ⑨	-	CuZn, Au	~1	7,5	~3

- ② Lötén
- ⑨ Crimpen

- ② Soldering
- ⑨ Crimping

- ② Soudage
- ⑨ Sertissage