


# Polyurethane-tyred wheel Ø 200 ball bearing, 1000kg

Heavy duty wheel

PRODUCT

Article number

23-514-200B20

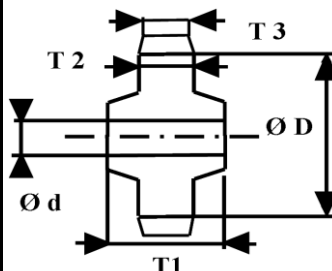

## Product Details

Wheel Rim : machined high-resistance engineered cast iron.

Tyre : cast bonded polyurethane.

Hub : symmetrical, with two ball bearings.

## Specifications

Wheel Diameter - ØD ± 1%	200 mm
Hub Type	Two ball bearings
Hub Length T1	60 mm ±1
Hub Length T1 on ball bearings	54 mm ±1
Width of Tread T2	50 mm ±1
Width of Tread-on floor T3	50 mm
Axle Hole Ø d	Ø 20 mm
Hardness of tread A ±3	A 93 Shore
Load capacity	1000 Kg
Temperature	-25 / +70 °C

TECHNICAL DATA

## Applications :

Materials handling of very heavy loads.

Low starting effort.

High degree of resistance to abrasion, wear, hydrocarbons and metal shavings.