


Connector ProTOP - Part no. 194A



- screw terminals
- cable gland and sealing
- strain relief and protection against kinking
- enclosure with thread lock and safety slide

| | |
|-----------------------|-----------------|
| Protection type | IP 44 |
| Ampere | 16 A |
| Poles | 4p |
| Voltage | 400 |
| Hertz | 50-60Hz |
| Earth position | 6h |
| Contact | standard |
| Connection technology | Screw terminals |

Std. Pack. 10 Qty.

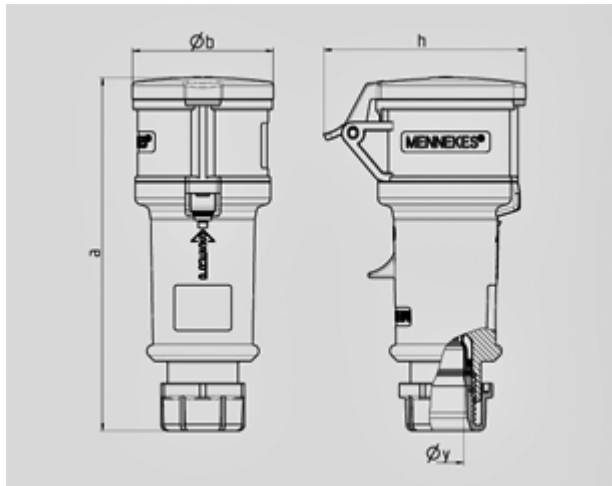

| Drawing | Amp. | 16 | | | 32 | | |
|--------------------------|-------|------|------|------|-----|-----|-----|
| | | 3 | 4 | 5 | 3 | 4 | 5 |
| 3 MB 60 | Poles | | | | | | |
| Dim. in mm | a | 160 | 174 | 172 | 214 | 214 | 210 |
| | b | 57 | 61 | 69 | 75 | 75 | 80 |
| | h | 83 | 92 | 98 | 100 | 100 | 108 |
| | y | 16 | 16 | 16 | 22 | 22 | 22 |
| Terminal for cond. cross | | 1 | 1 | 1 | 2,5 | 2,5 | 2,5 |
| section (mm²) min.-max. | | —2,5 | —2,5 | —2,5 | —6 | —6 | —6 |