

4000 - Model 125

Innovative multi-layer chemical barrier technology, Type 3/4/5 protection

Previously known as: MICROCHEM® 4000 - Model 125-G05

Heavy-duty multi-layer protective suit, guarding against more than 200 chemical hazards.



Industries

- Chemical
- Fire and Rescue
- Food Processing
- Life Sciences
- Mining
- Oil and gas
- Raw material preparation
- Automotive Aftermarket

Applications

- Contaminated Environments
- Chemical Handling
- Filling, blending and charging of raw materials
- Transferring liquids and solids
- Opening and draining pumps valves or lines
- Loading and unloading of process equipment
- Raw material handling
- Concentration mixing and palletisation
- Hazmat response
- Assembly and disassembly of equipment

KEY FEATURES & BENEFITS

- Exceptional protection, over 200 chemicals permeation tested, including chemical warfare agents
- Designed to protect, typical innovative features include dual zip systems and double cuffs
- Welded and taped seams, our highest barrier to liquids and particulates
- Enhanced comfort, knitted inner cuffs and inner textile type fabric improves wearer acceptance
- Anti-static, tested according to EN 1149-5

Technology



MICROCHEM™
Chemical Barrier Technology


Material Diagram




External film barrier layer

Core high barrier film layer

Non-woven inner layer

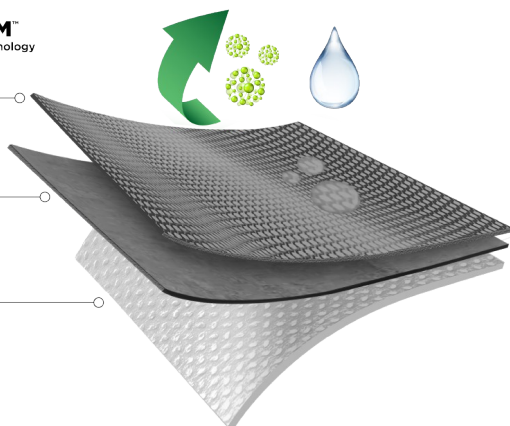

Seam Diagram

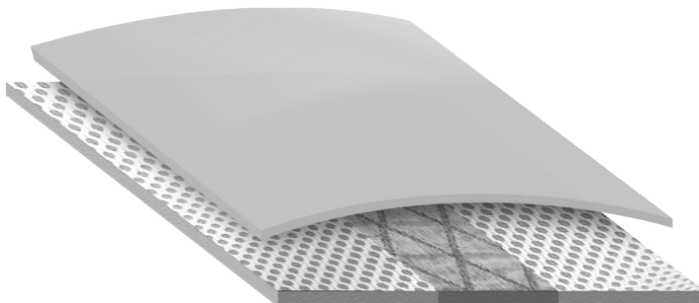

Performance Standards


TYPE 3-B


TYPE 4-B


TYPE 5-B


0598


EN 1073-2


EN 1149-5


EN 14126

EN ISO 13688:2013


NFPA 1992

Product Information

Product Information	
Available Sizes	S, M, L, XL, 2XL, 3XL, 4XL, 5XL
Color	Green
Country Of Origin	China
Models Available	103, 111, 121, 122, 125-G05, 132, 162
Packaging Overview	Individually Packed
Product Material	Multi-layer non-woven barrier Laminate fabric
Product Reference	4000 - Model 125
Standards Overview	CE CATEGORY III (Type 3-B, Type 4-B, Type 5-B, EN 1073-2, EN 14126, EN 1149-5)
Seam Type	Welded and Taped
Shelf Life	5 years
Style Number	G40T125D

For additional information visit us at www.ansell.com, or call us at

Europe, Middle East & Africa Region

Ansell Healthcare Europe NV
T: +32 (0) 2 528 74 00

North America Region

Ansell Healthcare Products LLC
T: +1 800 800 0444

Australia

Ansell Limited
T: +61 1800 337 041

Asia Pacific Region

Ansell Global Trading Center
T: +603 8310 6688

Latin America & Caribbean Region

Ansell Commercial Mexico S.A. de C.V.
T: +52 442 248 1544 / 248 3133

Ansell, ® and ™ are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending:
www.ansell.com/patentmarking © 2025 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.

