

Actuator

45-
290F.2000.113

Distribution by
Rs-online



<https://rs-online.eao.com/p/45-290F.2000.113>

Your product:



45-290F.2000.113 Actuator

FRONT

Front dimension:	Ø 29,5 mm
Front form:	Round
Front bezel colour:	Silver
Front bezel material:	Metal

MOUNTING

Design:	Raised
Mounting cut-out:	Ø 22.3 mm
Mounting type:	Panel mounting

MECHANICAL CHARACTERISTIC

Switching action:	Maintained (a) - Rest (a) - Maintained (a)
Switching positions:	3 positions
Switching angle:	45° left / 45° right / -45° ... +45°
Mechanical lifetime:	1 Mil. cycles of operation
Operating frequency:	1 800/h
Weight:	0.079 kg

AMBIENT CONDITION

IP front protection:	IP66, IP67, IP69K
Operating temperature:	- 25 °C ... + 70 °C
Storage temperature:	- 40 °C ... + 80 °C

Shock resistance:

According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms

Vibration resistance:

According to IEC 60068-2-6: 10 ... 500 Hz: 5 g

Climate resistance:

During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6

CERTIFICATE**REACH:**

REACH compliant

RoHS:

RoHS compliant

OTHER**Short Description:**


Actuator, Ø 22.3 mm, Ø 29,5 mm, Round, Silver, Metal, Maintained (a) - Rest (a) - Maintained (a), IP66, IP67, IP69K


Housing material:

Metal

Hints:

The standard lock: RONIS, T254

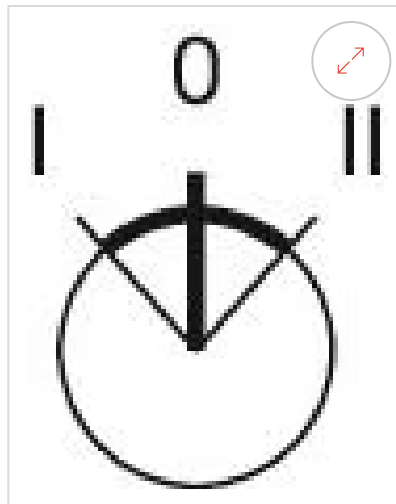Switching positions:**Wiring diagrams:****Mounting cut-outs:**

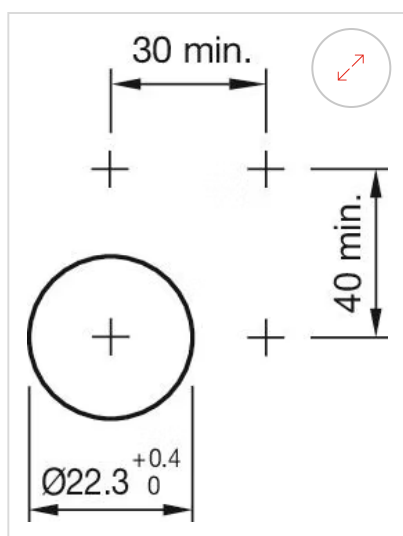

Dimension drawings:

