

UPS

Ellipse ASR

375/600/750/1000/1500 VA

Protecting business computer equipment

The highest level of protection for business computers

- ▶ **Ellipse ASR** UPSs not only provide a battery backed up supply to keep equipment operating when there is a power cut but also provide effective protection against damaging surges.
- ▶ **Ellipse ASR** (Advanced Surge Reduction) UPSs include a high performance surge protective device which complies with IEC 616431.
- ▶ **Ellipse ASR** UPSs also protect telephone, broadband and Ethernet 10/100 MB for complete protection.



The widest range of sockets

- ▶ 4 sockets (375/600/750 models) or 8 sockets (1000/1500 models)
- ▶ **Practical:** French, "Schuko" and universal sockets Also available with IEC sockets.



FR

DIN

UNI

IEC

The greatest flexibility

Extra flat for easy installation in all business environments:

- ▶ Vertical box format or below the desk
- ▶ Horizontal under a monitor
- ▶ 19" rack mounted (optional 2U kit)



The best compatibility with computer equipment

The USBs models are designed for compatibility with a wide variety of computers:

- ▶ Combined USB and serial ports
- ▶ Power management software available under Windows, Linux and Mac OS

Ideal protection for



SOHO



Large companies



SMEs

THE UNINTERRUPTIBLE POWER PROVIDER




MGE
UPS SYSTEMS

UPS - Ellipse ASR



Complete solution
(USB models are supplied with USB and serial port cables, Personal SolutionPac on CD-ROM)

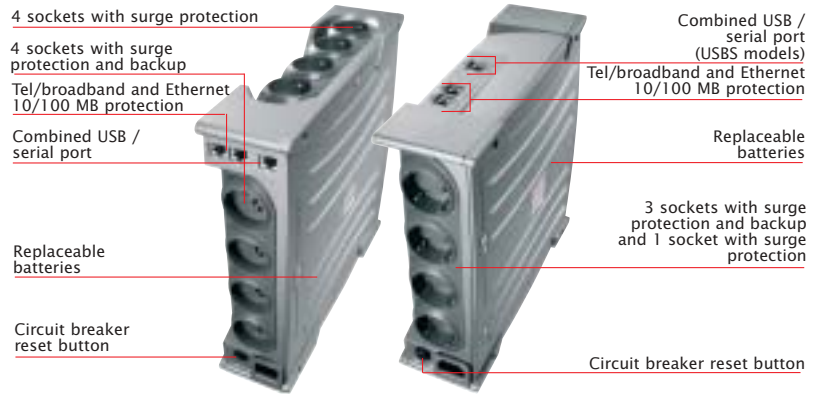

Ellipse ASR 1000/1500

Ellipse ASR 375/600/750

Associated communication

MGE Personal SolutionPac power management software: the essential option



Monitoring and system shutdown

- UPS control panel
- Log
- Alarms sent by SMS or e-mail
- When there is a long power cut, the system is shutdown (or hibernated under Windows) and restarted automatically
- Advanced personalisation features for expert users

Practical

- Compatible with Windows / MacOS / Linux
- USB or serial port connection
- Supplied on CD-ROM and can be downloaded from www.mgeups.com

MGE PowerServices™

2 year guarantee, including batteries

Free standard replacement for faulty units, including the batteries.

Extended guarantee ⁽¹⁾

- Warranty+: the guarantee of peace of mind, guarantee extended to 3 years with on site rapid replacement.

1: certain countries only, see www.mgeups.com/services.

Technical characteristics

Ellipse ASR	375	600 600 USBs	750 USBs	1000 USBs	1500 USBs	XL	
Rating (VA / Watt)	375/225	600/360	750/450	1000/600	1500/900	420/250	
Application							
Multi-way sockets:	4	4	4	8	8	5	
French, Schuko, Universal, IEC							
Sockets with surge protection and backup / sockets with surge protection for peripherals	3/1	3/1	3/1	4/4	4/4	4/1	
Characteristics							
Input voltage	184V to 264V (adjustable from 161V to 284V)						
Output voltage	230V (settable to 220V, 230V, 240V)						
Frequency	50-60Hz autoselect						
Surge protection	Integral surge protection device to IEC 61643-1, Total surge absorption: 525 Joules						
Circuit breaker	with reset						
Battery							
Replaceable battery	Compact sealed lead acid						
Battery charger	Operates when the UPS is under power						
Battery test	✓	✓	✓	✓	✓	✓	
Cold start (no mains)	✓	✓	✓	✓	✓	✓	
Deep discharge protection	4 hours	4 hours	4 hours	4 hours	4 hours	48 hours	
Battery replacement indicators	LED + audible alarm						
50% load backup	28 min	15 min	13 min	18 min	16 min	4 EXB : 15h	
70% load backup	16 min	7 min	6 min	9 min	8 min	4 EXB : 9h 20 min	
Communication (uniquement sur les versions USBs)							
Communications port (USBs models)	–	Combined USB and serial port	Combined USB and serial port	Combined USB and serial port	Combined USB and serial port	–	
Software supplied as standard (USBs models)	–	Compatible with: Windows XP/2003/2000/98/95/Me/NT, Mandrake Linux, Mandriva Linux, Red Hat Linux, Suse Novell, Debian GNU/Linux, Mac OS X				–	
Line protection	Tel/Fax/Modem/Internet et Ethernet 10/100 MB (available for all models)					–	
Standards							
Safety	IEC/EN 62040-1-1, IEC/EN 60950, CB Report, CE mark						
EMC	IEC 62040-2 / EN 50 091-2						
Surge protection	IEC 61643-1						
Mounting, dimensions and weight							
Dimensions (HxWxD (mm))	270 x 82 x 265	270 x 82 x 265	270 x 82 x 265	305 x 80 x 312	317 x 80 x 390	317 x 80 x 390	
Weight (kg)	4,2	4,2	4,4	8,1	11	11	
19" rack mounting kit	2U	2U	2U	2U	2U	2U	
Part numbers							
Ellipse ASR	375	600	600 USBs	750 USBs	1000 USBs	1500 USBs	XL
French sockets	66 761	66 765	66 769	66 773	66 777	66 781	66 792
Schuko sockets	66 762	66 766	66 770	66 774	66 778	66 782	66 793
UNI sockets	66 763	66 767	66 771	66 775	66 779	66 783	66 794
IEC sockets	66 764	66 768	66 772	66 776	66 780	66 784	66 795
Accessories							
19" rack mounting kit	66 785						
Ellipse EXB						66791	

MGE UPS SYSTEMS

Headquarters
140, avenue Jean-Kuntzmann
Inovallée - Montbonnot Saint-Martin
38334 Saint-Ismier Cedex - France
Tel.: +33 (0)4 76 18 30 00
EASR493UK-08/06

THE UNINTERRUPTIBLE POWER PROVIDER

