

ARCA 405021ST No MP

FIBOX
Enclosing innovations



Sample image

Order symbol : ARCA 405021ST No MP

Product nr : 8121105N

Description : Cabinet, PC


Remarks : Transparent cover, Swinghandle, hinges on the short side, without mountingplate

EAN : 6418074318848

El. number :

- Finland : 3425159
- Denmark : 8212056336
- Sweden : 2507053

Including : Cabinet base, door with PUR gasket. 3mm double bit lock(s) with key. S versions with swinghandle 2-point locking system. Door guide included.

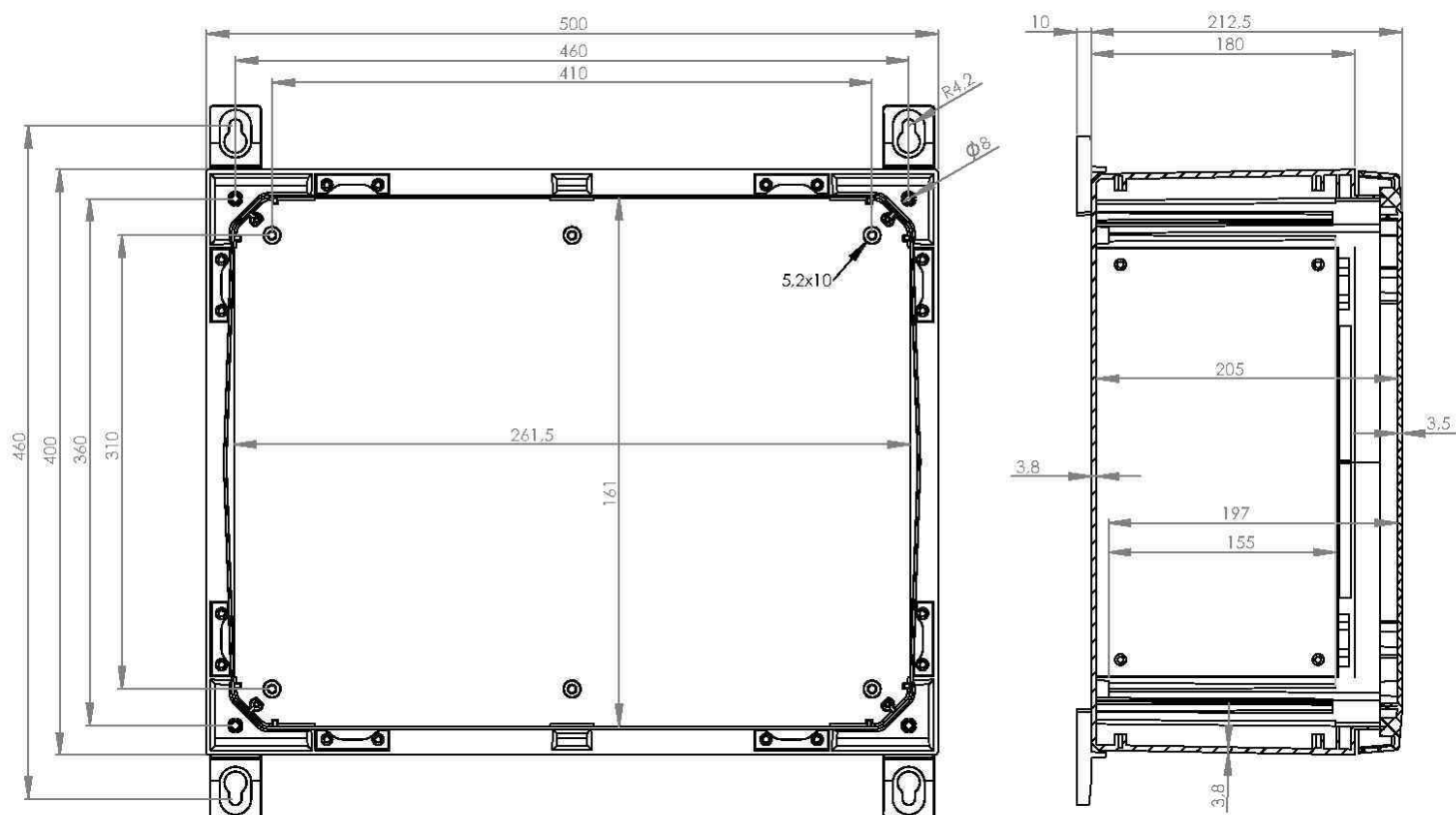

Dimensions :

	Height	Width	Depth
mm :	400	500	210
inch :	15.75	19.69	8.27

Materials :

Material :	Polycarbonate
Base colour :	RAL_7035
Cover colour :	Smoked grey
Gasket material :	Polyurethane

Temperatures :

Temperature °C (continuous) :	-40 ... 80
Temperature °F (continuous) :	-40 ... 175

Accessories :

MPX ARCA 5040	Mounting plate (450x350 mm) (450 x 350 x 5)
MPMP ARCA 5040	Mounting plate multiperforated (450x350x2 mm - ø3.6 mm) (450 x 350 x 1.5)
DSP ARCA HRS	Door stopper ARCA, horizontal, right, small (15 x 104 x 16)
DRS ARCA 405021	DIN rail frame set (485 x 385 x 35)
DSP ARCA HLS	Door stopper ARCA, horizontal, left, small (15 x 104 x 16)
MPP ARCA 4050	Mounting plate perforated (450x350x2 mm - 26x11 mm) (350 x 450 x 2)
MPS ARCA 5040	Mounting plate (450x350x2 mm) (450 x 350 x 2)
PMK ARCA 50	PoleMounting kit, for pole ø100-300mm (485 x 385 x 35)
IDS ARCA 4050	Inner door set
RCS ARCA 4050	Rain canopy set for size 4050 (30 x 500 x 20)

Ratings :

Ingress protection (EN 60529):	IP65;
Impact Resistance (EN 62262):	IK09;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes
UV resistance :	UL 746C
Flammability Rating :	UL 94 5VA
Glow Wire Test (IEC 695-2-1) °C :	960C

Certificates :

Certificate FI 40467