


Geberit Mapress Stainless Steel adaptor union with male thread

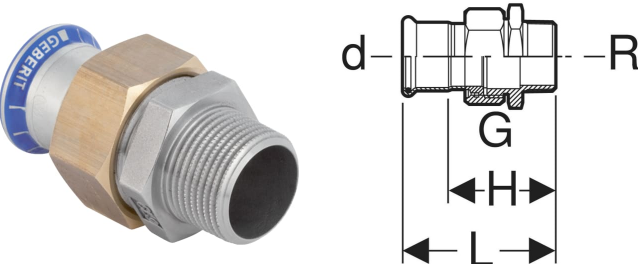

Example image

APPLICATION PURPOSES

- For cold and hot potable water
- For cooling and heating water without antifreeze agent
- For service water and process water
- For treated water
- For rainwater with a pH value ≥ 5.5
- For grey and black water with a pH value ≥ 5.5
- For extinguishing water (wet)
- For extinguishing water (wet/dry, dry)
- For sprinklers (wet)

- For chemicals and technical liquids
- For compressed air (oil purity class 0–3)
- For negative pressure
- For inert gases (e.g. nitrogen)
- For industrial gases (e.g. acetylene, shielding gases)
- For technical building systems, industry and shipbuilding

- Union nut made of brass
- Seal ring made of CIIR, black
- Flat gasket made of EPDM
- Pressing socket with transparent protection plug

CHARACTERISTICS

- Pressing indicator
- Leaky if unpressed

TECHNICAL DATA

Medium temperature with flat gasket EPDM	0–100 °C
Product material	CrNiMo steel 1.4401 (EN 10088)

Art. no.	DN	d, ø mm	R "	G "	L cm	H cm
35330	12 / 15	15	1/2	3/4	6.4	4.4
35331	12 / 20	15	3/4	3/4	6.6	4.6
35332	15	18	1/2	3/4	6.4	4.4

Art. no.	DN	d _ø mm	R "	G "	L cm	H cm
35333	15 / 20	18	3/4	3/4	6.6	4.6
35334	20 / 15	22	1/2	1	6.7	4.6
35335	20	22	3/4	1	6.8	4.7
35336	20 / 25	22	1	1	7.3	5.2
35337	25	28	1	1 1/4	7.8	5.5
35338	32	35	1 1/4	1 1/2	8.5	5.9
35339	40	42	1 1/2	1 3/4	9	6
35340	50	54	2	2 3/8	10.3	6.8