



Brand of NTN corporation

Technical data

UCEHE206

Bearing units




Grey cast housing, radial insert ball bearing with socket set screws, seal with slinger

KIT CONTENT

UC206G2, EHE206

VISUAL (S)

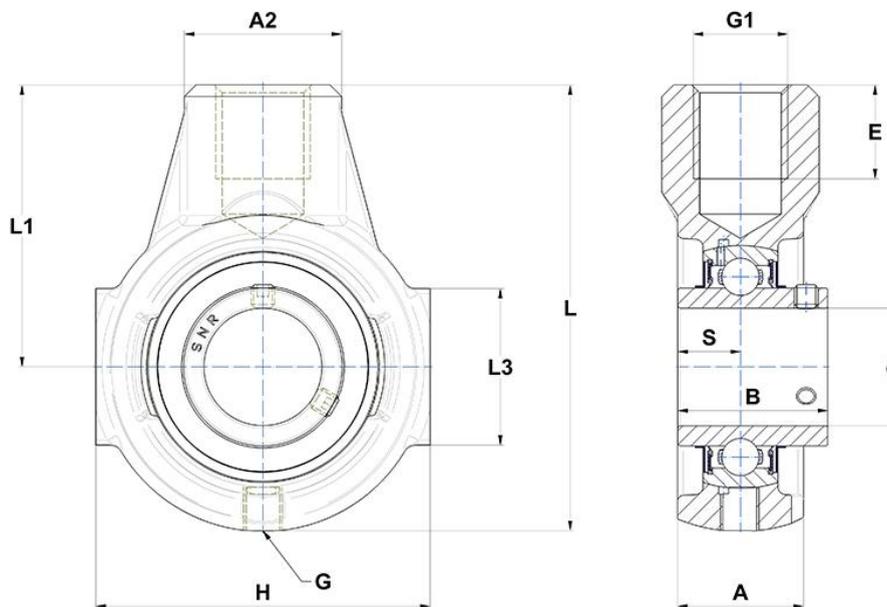

PRODUCT DEFINITION

Brand	SNR
A - Housing width	32 mm
A2	40 mm
B - Width of Inner Ring	38,1 mm
d - Shaft diameter	30 mm
E - Mounting hole thread depth	24 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

G - Grease fitting	R1/8"
G1 - Thread size	M24
H - Housing length, width or diameter	85 mm
L - Housing length	114 mm
L1 - Distance attachment end face to bearing centerline	72 mm
L3 - Length of guidance slot/face	40 mm
S - Distance front side/bearing centre	15,9 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	19500000 mN
C0 - Static load rating	11200000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Mass	1,02 kg
Recommended tightening torque for set screw	5.5 N-m

