




LED Spot PAR38 E27 DIM 15W (120W) 1150lm 840 40° IP65

Article number: 145517

BAI BaiSpot LED PAR38 E27 15W (120W) 1150lm 4000K 40° Dimmable 230V-240V 121x132mm Only the cover is IP65 LED-lamp

The so-called LED spots from the BaiSpot series are characterized by a much longer lifespan and significantly less energy consumption than their halogen predecessors. Due to the compact design, they are easily interchangeable. Spots are mainly used to provide directed light from the ceiling or wall. This version of the BaiSpot is dimmable. Use the correct LED dimmer. IP65 front disc: suitable for outdoor use if the lamp base is protected against contact with water. Ambient temperature range: -20°C to +45°C.

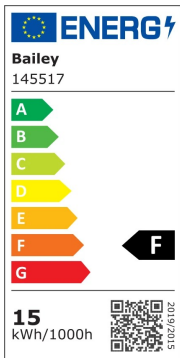

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED Spot PAR38 E27 DIM 15W (120W) 1150lm 840 40° IP65
Brand	Bailey
Productseries	BaiSpot LED MV
Producttype	PAR38

ETIM specifications

Socket	E27
Luminous flux [lm]	1150 - 1150
Nominal voltage [V]	220 - 240
Lamp power [W]	15 - 15
Colour temperature [K]	4000 - 4000
Diameter [mm]	121
Length [mm]	132
Dimmable	Yes
Lamp shape	Reflector
Beam angle [°]	40 - 40
Colour	White
Type of glass/cover	Clear
Lamp designation	PAR38
Colour rendering index CRI	80-89
Voltage type	AC
Filament lamp	No
Luminous intensity [cd]	2066
Rated luminous flux according to IEC 62612 [lm]	77
Power factor	0.8
Nominal current [mA]	70 - 70
Colour of light according to EN 12464-1	Neutral white 3300-5300 K
Housing colour	White
Average nominal lifetime [h]	15000
Degree of protection (IP)	IP65
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	15000
Weighted energy consumption in 1000 hours [kWh]	15
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG1
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	Yes
Dimming phase cut-on (leading edge)	Yes
Dimming Touch and Dim	No
Dimming Zigbee	No

Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	F
With twilight switch	No

Alternative articles



145516
LED Spot PAR38 E27 DIM 15W
(120W) 1150lm 830 40° IP65

Predecessor



80100041354
LED Spot PAR38 E27 18W
1450lm 840 40° Alu DIM IP65