




Wirable plug

SSTGH040ZDSFKSK

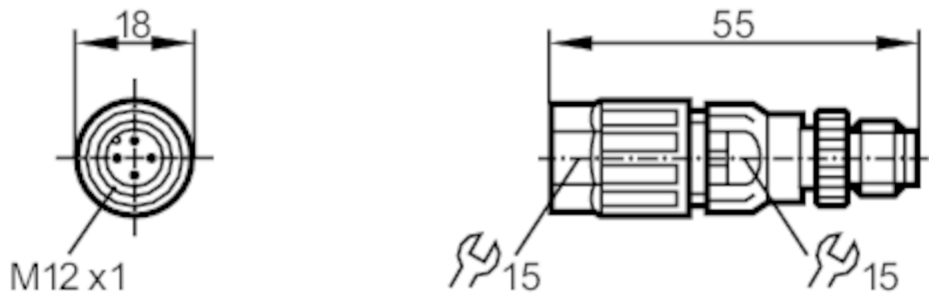

| Electrical data         |      |                     |
|-------------------------|------|---------------------|
| Operating voltage       | [V]  | < 250 AC/DC         |
| Max. current load total | [A]  | 4                   |
| Operating conditions    |      |                     |
| Ambient temperature     | [°C] | -25...60            |
| Protection              |      | IP 67               |
| Mechanical data         |      |                     |
| Weight                  | [g]  | 15.4                |
| Dimensions              | [mm] | 18 x 18 x 55        |
| Moulded-body material   |      | PA 6.6              |
| Material nut            |      | zinc, nickel-plated |
| Remarks                 |      |                     |
| Pack quantity           |      | 1 pcs.              |

| Electrical connection                                                                                                     |  |
|---------------------------------------------------------------------------------------------------------------------------|--|
| insulation displacement technology: 0.34...0.75 mm²; Core insulation: PVC / PE; (Ø ...2.5 mm); Cable sheath: Ø 4...7.5 mm |  |

| Electrical connection - plug                                                                |  |
|---------------------------------------------------------------------------------------------|--|
| Connector: 1 x M12, straight; coding: A; Moulded body: PA 6.6; Locking: zinc, nickel-plated |  |



# E11144

## Wirable plug

SSTGH040ZDSFKSK



### Connection

