


NSYMR86

Monobloc perforated plates H800xW600mm with universal perforations 11x26mm

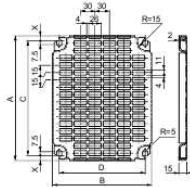

Main

Range	Spacial
Accessory / separate part category	Mounting accessory
Product or component type	Mounting plate
Device application	Multi-purpose
For enclosure nominal dimensions	800 mm W: 600 mm 800 mm W: 1200 mm
Mounting location	Step slide Direct fixing on backstuds
Mounting plate description	Telequick perforated
Range compatibility	Spacial CRN Spacial S3D Spacial S3X Thalassa PLM
Quantity per set	Set of 1
Material	Steel
Surface finish	Zinc coated

Complementary

Fixing mode	Screwed on backstuds - screw type M8 By fixing element
Height	750 mm
Width	551 mm
Depth	15 mm
Thickness	2 mm
Product weight	3.2 kg
Number of slots	867
Variant particularity	With enclosures H800 x W1200 Installation in rear of enclosure
Cut-out dimensions	11 x 26 mm

Environment

Offer Sustainability

Sustainable offer status	Green Premium product
RoHS (date code: YYWW)	Compliant - since 0940 - Schneider Electric declaration of conformity
REACH	Reference not containing SVHC above the threshold
Product environmental profile	Available
Product end of life instructions	Need no specific recycling operations

Contractual warranty

Warranty period	18 months
-----------------	-----------

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.