




# Datasheet

## RS PRO SPIRALFLEX HD - SPH SERIES

Stock number: See Table

EN

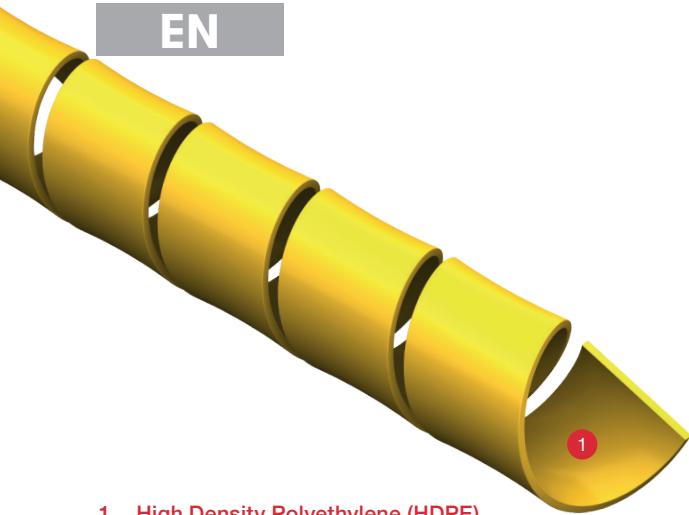

1. High Density Polyethylene (HDPE)



### Applications:

- Hydraulic
- Pneumatic
- Paint spray
- Chemical or industrial hoses

Offers quick and simple protection to all types of hydraulic and pneumatic hoses. A cost-effective solution to shocks, abrasion and deterioration, helping reduce equipment downtime and maintenance costs.

Easily deployed to new or existing hydraulic and pneumatic assemblies, without the use of any tools.

### Key Features:

- Simple to use with one or several hoses.
- Smooth rounded edges prevent damage to hose assemblies or equipment during installation and use.
- Can withstand a temperature range -40°C to +138°C.
- Suitable for contact with hydraulic fluids including glycol and phosphate based products.

### Sizes:

Available in 20m and 50m coils

### Colours:

Black, red and yellow

Other colours are available upon request

### Packaging:

Supplied boxed for ease of handling.



Black	Red	Yellow	Size Range	External Diameter	Wall Thickness	Weight per coil	Coil Length
1860554	1860563	1860574	11.5-16mm	12mm	1.25mm	2.9 Kg	50m
1860555	1860564	1860575	11.5-16mm	16mm	1.5mm	2.9 Kg	50m
1860556	1860565	1860576	14-20mm	20mm	1.8mm	5.1 Kg	50m
1860557	1860567	1860577	20-25mm	25mm	2mm	6.4 Kg	50m
1860558	1860568	1860578	25-32mm	32mm	2.4mm	11.5 Kg	50m
1860559	1860569	1860579	32-40mm	40mm	2.4mm	13.4 Kg	50m
1860560	1860570	1860580	38-50mm	50mm	3mm	8.5 Kg	20m
1860561	1860571	1860581	50-63mm	63mm	3.5mm	12.6 Kg	20m
1860562	1860573	1860582	60-75mm	75mm	3.8mm	16.3 Kg	20m